

Stainless steel chain sprocket

DIN 06B-1

304 stainless steel

3/8"



stainless
steel




- Pitch 3/8" (9.525mm) (DIN 06B-1)
- Roller diameter 6.35mm
- Material:
stainless steel AISI 304
- **We are unable to modify these parts**
- *Pilot bore dimensions are given as a guide only and are subject to change

Options

- American pitch (ASA) on request
- Custom made versions are available

Accessories

- SBS-375 chain

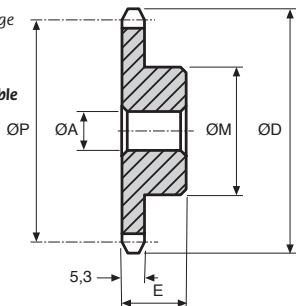

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-12%	On request

Part number	Z Teeth	ØP	ØD	ØM	*Pilot bore not guaranteed ØA	E	Price each. 1 to 3
PCS37-12/SS	12	36,80	40,0	25	8	25	13,05 €
PCS37-13/SS	13	39,80	43,0	28	10	25	14,11 €
PCS37-15/SS	15	45,81	49,3	34	10	25	20,11 €
PCS37-16/SS	16	48,82	52,3	37	10	28	25,74 €
PCS37-17/SS	17	51,83	55,3	40	10	28	27,33 €
PCS37-18/SS	18	54,85	58,3	43	10	28	28,47 €
PCS37-19/SS	19	57,87	61,3	46	10	28	29,09 €
PCS37-20/SS	20	60,89	64,3	46	10	28	30,76 €
PCS37-21/SS	21	63,91	68,0	48	12	28	30,96 €
PCS37-23/SS	23	69,95	73,5	52	12	28	34,55 €
PCS37-25/SS	25	76,00	80,0	57	12	28	37,98 €
PCS37-30/SS	30	91,12	94,7	60	12	30	44,71 €

Dimensions in mm

Our other products



ZG1

Plastic spur gear,
Machined plastic
(delrin)




RFVcap

Stainless steel
protective cover,
Closed protective
cover



PTA150

 Articulated levelling
foot, pressed base
Ø150, Ø 150



ACLBTS

Closing system for
aluminium profile, 90°
bracket for spherical
end...



DHX

Dowel pin internal
thread, Extractable
DIN 7979D



SH0

Parallel axis helical
gear, Machined plastic
(delrin)



NPTF20

Spacer for tube
carrier, Fixing
accessory Ø10 to Ø14



PRF_PGN

Door handle for
aluminium profile,
Handle with lock
suitable



BOXINS300

Box set of self tapping
inserts, Boxed set -



 
BPPL

Assembly tool for
carrier ball, Mounting



SCH


Horizontal hook
toggle clamp,



KITbuh

24V DC motorisation
kit, Planetary gears

 Complementary products



SBS_M

Single chain supplied
by the metre,
Stainless steel



PCS37

Chain sprocket - steel,
9.525mm (DIN06B-1)



TCXR

Automatic chain
tensioner, With
stainless steel
sprocket



PCS_PA6

Plastic sprocket,
9.525mm (DIN 06B-1)