

Stainless steel chain sprocket

DIN 06B-1


304 stainless steel

3/8"



- Pitch 3/8" (9.525mm) (DIN 06B-1)
- Roller diameter 6.35mm
- Material:
stainless steel AISI 304
- **We are unable to modify these parts**
- *Pilot bore dimensions are given as a guide only and are subject to change

stainless steel

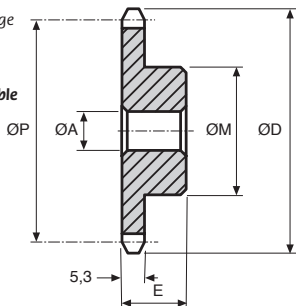

Options

- American pitch (ASA) on request
- Custom made versions are available

Accessories

- SBS-375 chain

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-12%	On request

Part number	Z Teeth	ØP	ØD	ØM	*Pilot bore not guaranteed ØA	E	Price each. 1 to 3
PCS37-12/SS	12	36,80	40,0	25	8	25	13,05 €
PCS37-13/SS	13	39,80	43,0	28	10	25	14,11 €
PCS37-15/SS	15	45,81	49,3	34	10	25	20,11 €
PCS37-16/SS	16	48,82	52,3	37	10	28	25,74 €
PCS37-17/SS	17	51,83	55,3	40	10	28	27,33 €
PCS37-18/SS	18	54,85	58,3	43	10	28	28,47 €
PCS37-19/SS	19	57,87	61,3	46	10	28	29,09 €
PCS37-20/SS	20	60,89	64,3	46	10	28	30,76 €
PCS37-21/SS	21	63,91	68,0	48	12	28	30,96 €
PCS37-23/SS	23	69,95	73,5	52	12	28	34,55 €
PCS37-25/SS	25	76,00	80,0	57	12	28	37,98 €
PCS37-30/SS	30	91,12	94,7	60	12	30	44,71 €

Dimensions in mm

Our other products



PTA100

Articulated levelling foot, pressed base Ø100, Ø 100



AXTR

Axle for tensioner pulley, Shaft



MHMEP

Arm with rotating handle, Prebored



EX

Optional shaft for E-type gear reducers, E Gearboxes single sided ou...



EBM

Steel U bolt, Steel



BAG0

Locking rings in steel, Steel



CHMR30

Worm and wheel gear reducer, up to 28 Nm



CHB

Double output shaft, For CHB gearbox




SSB

Stainless steel bevel gear, 1:1



RFK58B

Hypoid gearbox - Stainless steel, up to 28 Nm

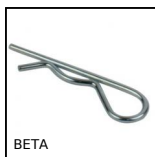

BETA


Hitch pin, Hitch



ACM_DZ

Clip for bonnet fastener, Clip

Complementary products

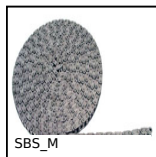

SBS_M

Single chain supplied by the metre, Stainless steel



PCS37

Chain sprocket - steel, 9.525mm (DIN06B-1)



TCXR

Automatic chain tensioner, With stainless steel sprocket



PCS_PA6

Plastic sprocket, 9.525mm (DIN 06B-1)