

Stainless steel chain sprocket

DIN 06B-1


304 stainless steel

3/8"



- Pitch 3/8" (9.525mm) (DIN 06B-1)
- Roller diameter 6.35mm
- Material:
stainless steel AISI 304
- **We are unable to modify these parts**
- *Pilot bore dimensions are given as a guide only and are subject to change

stainless steel

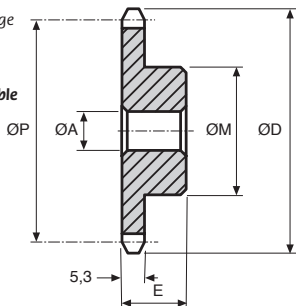

Options

- American pitch (ASA) on request
- Custom made versions are available

Accessories

- SBS-375 chain

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-12%	On request

Part number	Z Teeth	ØP	ØD	ØM	*Pilot bore not guaranteed ØA	E	Price each. 1 to 3
PCS37-12/SS	12	36,80	40,0	25	8	25	13,05 €
PCS37-13/SS	13	39,80	43,0	28	10	25	14,11 €
PCS37-15/SS	15	45,81	49,3	34	10	25	20,11 €
PCS37-16/SS	16	48,82	52,3	37	10	28	25,74 €
PCS37-17/SS	17	51,83	55,3	40	10	28	27,33 €
PCS37-18/SS	18	54,85	58,3	43	10	28	28,47 €
PCS37-19/SS	19	57,87	61,3	46	10	28	29,09 €
PCS37-20/SS	20	60,89	64,3	46	10	28	30,76 €
PCS37-21/SS	21	63,91	68,0	48	12	28	30,96 €
PCS37-23/SS	23	69,95	73,5	52	12	28	34,55 €
PCS37-25/SS	25	76,00	80,0	57	12	28	37,98 €
PCS37-30/SS	30	91,12	94,7	60	12	30	44,71 €

Dimensions in mm

Our other products



LVT

Miniature motorised actuator 2A, 2 amperers




GPB

Threaded spherical knob, Moulded thread



MC

Self-compensating shock-absorber, Self-compensating - without adjust...

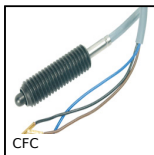

CFC

Spring loaded position switch, Electric contact



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm



GAL 42

Guide roller for plate chain return, Without ball bearing



BAGtr

Lead screw clamping collar, Aluminium



EMS

Stainless steel knurled thumb nut, Knurled



VRBS

Folding lifting ring for welding, Folding - for welding



SUP

Self-centering clamping hub steel, Without locknut



CHTRP


Single and dual output gearboxes, Up to 9,1 Nm



PSG125HC

Skive hobbed spur gears - precision range, Case hardened steel 20NCD2

Complementary products

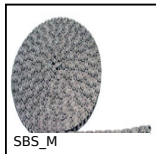

SBS_M

Single chain supplied by the metre, Stainless steel



PCS37

Chain sprocket - steel, 9.525mm (DIN06B-1)



TCXR

Automatic chain tensioner, With stainless steel sprocket



PCS_PA6

Plastic sprocket, 9.525mm (DIN 06B-1)