

Chain sprocket **DIN 08B-1**



Pitch 1/2"

Steel

- Pitch 1/2" (12.7mm) (DIN 08B-1)
- Roller diameter 8.51mm
- Material: Steel C43
- HPC are unable to modify these parts


Options

- American pitch (ASA) on request
- The prebore dimensions are given as a guide only and are subject to change
- Custom made versions available

Accessories

- SBR-500 and SBS-500 chains

Economy range

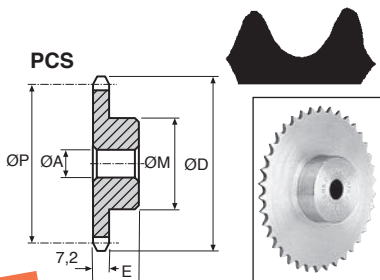

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP	ØD	ØM	ØA	E	Stock*	Price each 1 to 5
PCS50-8	8	33,18	37,2	20	10	25	✓	1,70 €
PCS50-9	9	37,13	41,0	24	10	25	✓	2,40 €
PCS50-10	10	41,10	45,2	26	10	25	✓	3,11 €
PCS50-12	12	49,07	53,0	33	10	28	✓	4,25 €
PCS50-15	15	61,09	65,5	45	10	28	✓	5,78 €
PCS50-16	16	65,10	69,5	50	12	28	✓	6,13 €
PCS50-18	18	73,14	77,8	56	12	28	✓	7,51 €
PCS50-20	20	81,19	85,8	64	12	28	✓	10,16 €
PCS50-21	21	85,22	89,7	68	14	28	✓	10,70 €
PCS50-22	22	89,24	93,8	70	14	28	✓	11,01 €
PCS50-23	23	93,27	98,2	70	14	28	-	11,57 €
PCS50-24	24	97,29	101,8	70	14	28	✓	11,76 €
PCS50-25	25	101,33	105,8	70	14	28	✓	12,44 €
PCS50-26	26	105,36	110,0	70	16	30	✓	13,22 €
PCS50-27	27	109,40	114,0	70	16	30	✓	13,41 €
PCS50-28	28	113,42	118,0	70	16	30	✓	13,76 €
PCS50-29	29	117,46	122,0	80	16	30	✓	15,69 €
PCS50-30	30	121,50	126,1	80	16	30	✓	17,35 €
PCS50-31	31	125,54	130,2	90	16	30	-	18,44 €
PCS50-32	32	129,56	134,3	90	16	30	✓	18,68 €
PCS50-33	33	133,60	138,4	90	16	30	-	19,23 €
PCS50-34	34	137,64	142,6	90	16	30	-	21,06 €
PCS50-35	35	141,68	146,7	90	16	30	✓	21,65 €
PCS50-36	36	145,72	151,0	90	20	35	✓	23,95 €
PCS50-37	37	149,76	154,6	90	20	35	-	24,69 €
PCS50-38	38	153,80	158,6	90	20	35	✓	24,92 €
PCS50-39	39	157,83	162,7	90	20	35	-	26,10 €
PCS50-40	40	161,87	166,8	90	20	35	✓	26,64 €

*Depending on availability - Dimensions in mm

Our other products



ACLEPP

Right angled bracket for aluminium profile, 4 holes



CQA30

Adjustment slide-system miniature, 30



SRG

Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



PSG08S

Spur gear - precision range, Stainless steel 303



HK

Manual locking clamp, Manual locking clamp LRX



DGSA

Male rod ends, Steel / steel - Economy range




PSG1S

Spur gear - precision range, Stainless steel 316



CFF

 Female rod ends DIN ISO12240-4, Steel / bronze



G0

Steel spur gear, Steel 20NCD2



UGH40

H Type Guide units, For Ø40 actuators



BPMc

Stainless steel slotted spring plunger with ceramic ball tip, 303



AT10courroie


AT type timing belt, AT10 Steel cored polyurethane

Complementary products



SUA4

Single chain supplied by the metre, Steel

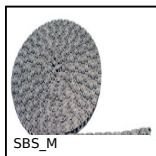

SBS_M

Single chain supplied by the metre, Stainless steel



TCLar

Automatic chain tensioner, With wide guide



TCSH

Automatic chain tensioner, With support