

Chain sprocket **DIN 10B-1**



Pitch 5/8"

Steel

- Pitch 5/8" (15.875 mm) (DIN 10B-1)
- Roller diameter 10.16mm
- Material: Steel C43
- **We are unable to modify these parts**

Options


- American pitch (ASA) on request
- The prebore dimensions are given as a guide only and are subject to change
- **Custom made versions available**

Accessories

- SBR-625 and SBS-265 chains

Economy range

PCS

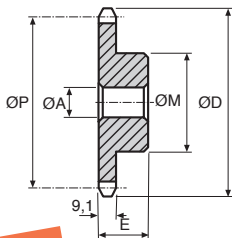

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP	ØD	ØM	ØA	E	Stock*	Price each 1 to 5
PCS62-8	8	41,48	47,0	25	10	25	✓	2,74 €
PCS62-9	9	46,42	52,6	30	10	25	-	3,77 €
PCS62-10	10	51,37	57,5	35	10	25	✓	3,77 €
PCS62-13	13	66,32	73,0	47	12	30	✓	6,98 €
PCS62-15	15	76,36	83,0	57	12	30	✓	8,63 €
PCS62-16	16	81,37	88,0	60	14	30	✓	9,62 €
PCS62-17	17	86,39	93,0	60	14	30	✓	10,34 €
PCS62-18	18	91,42	98,3	70	14	30	✓	11,57 €
PCS62-20	20	101,49	108,4	75	14	30	✓	13,41 €
PCS62-21	21	106,52	113,4	75	16	30	✓	14,45 €
PCS62-22	22	111,55	118,0	80	16	30	-	15,82 €
PCS62-23	23	116,58	123,4	80	16	30	-	16,60 €
PCS62-24	24	121,62	128,3	80	16	30	-	17,35 €
PCS62-25	25	126,66	134,0	80	16	30	-	18,01 €
PCS62-26	26	131,70	139,0	85	20	35	-	21,51 €
PCS62-27	27	136,75	144,0	85	20	35	-	23,29 €
PCS62-28	28	141,78	148,7	90	20	35	-	24,37 €
PCS62-29	29	146,83	153,8	90	20	35	-	25,81 €
PCS62-30	30	151,87	158,8	90	20	35	✓	26,57 €
PCS62-31	31	156,92	163,9	95	20	35	-	28,65 €
PCS62-32	32	161,95	168,9	95	20	35	-	29,72 €
PCS62-33	33	167,00	174,5	95	20	35	-	30,93 €
PCS62-34	34	172,05	179,0	95	20	35	-	31,89 €
PCS62-35	35	177,10	184,1	95	20	35	-	33,04 €
PCS62-38	38	192,24	199,2	100	20	35	-	37,57 €
PCS62-39	39	197,29	204,2	100	20	35	-	39,05 €
PCS62-40	40	202,34	209,3	100	20	35	✓	40,32 €

*Depending on availability - Dimensions in mm

Our other products



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



CHM63

Worm and wheel gear reducer, up to 196 Nm



SER

Magnetic doorstop for aluminium profile, Magnetic doorstop



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard



PGM52-M4

Pull handle, Aluminium



BOXKK

Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



 
M

Bellows cover, Accessory:



BPQ

Quadro linear ball bearing unit, Included 4 linear ball bearings



CTs

Universal joint, telescopic, Inox, Light



LVT

Miniature motorised actuator 4A, 4 amperes



NPTR_M

Adjustable cross clamp, Adjustable



TS01_TW01

Drylin® T linear slide, up to 7000 N

Complementary products



SUA4

Single chain supplied by the metre, Steel



SBS_M

Single chain supplied by the metre, Stainless steel



PTR

Idler chain sprocket, For standard applications



PC562SS

Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)