

Chain sprocket **DIN 10B-1**



Pitch 5/8"

Steel

- Pitch 5/8" (15.875 mm) (DIN 10B-1)
- Roller diameter 10.16mm
- Material: Steel C43
- **We are unable to modify these parts**

Options


- American pitch (ASA) on request
- The prebore dimensions are given as a guide only and are subject to change
- **Custom made versions available**

Accessories

- SBR-625 and SBS-265 chains

Economy range

PCS

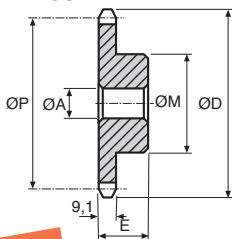

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP	ØD	ØM	ØA	E	Stock*	Price each 1 to 5
PCS62-8	8	41,48	47,0	25	10	25	✓	2,74 €
PCS62-9	9	46,42	52,6	30	10	25	-	3,77 €
PCS62-10	10	51,37	57,5	35	10	25	✓	3,77 €
PCS62-13	13	66,32	73,0	47	12	30	✓	6,98 €
PCS62-15	15	76,36	83,0	57	12	30	✓	8,63 €
PCS62-16	16	81,37	88,0	60	14	30	✓	9,62 €
PCS62-17	17	86,39	93,0	60	14	30	✓	10,34 €
PCS62-18	18	91,42	98,3	70	14	30	✓	11,57 €
PCS62-20	20	101,49	108,4	75	14	30	✓	13,41 €
PCS62-21	21	106,52	113,4	75	16	30	✓	14,45 €
PCS62-22	22	111,55	118,0	80	16	30	-	15,82 €
PCS62-23	23	116,58	123,4	80	16	30	-	16,60 €
PCS62-24	24	121,62	128,3	80	16	30	-	17,35 €
PCS62-25	25	126,66	134,0	80	16	30	-	18,01 €
PCS62-26	26	131,70	139,0	85	20	35	-	21,51 €
PCS62-27	27	136,75	144,0	85	20	35	-	23,29 €
PCS62-28	28	141,78	148,7	90	20	35	-	24,37 €
PCS62-29	29	146,83	153,8	90	20	35	-	25,81 €
PCS62-30	30	151,87	158,8	90	20	35	✓	26,57 €
PCS62-31	31	156,92	163,9	95	20	35	-	28,65 €
PCS62-32	32	161,95	168,9	95	20	35	-	29,72 €
PCS62-33	33	167,00	174,5	95	20	35	-	30,93 €
PCS62-34	34	172,05	179,0	95	20	35	-	31,89 €
PCS62-35	35	177,10	184,1	95	20	35	-	33,04 €
PCS62-38	38	192,24	199,2	100	20	35	-	37,57 €
PCS62-39	39	197,29	204,2	100	20	35	-	39,05 €
PCS62-40	40	202,34	209,3	100	20	35	✓	40,32 €

*Depending on availability - Dimensions in mm

Our other products



SRG

Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



IN1

Internal gear, Steel 20NCD2



PRF_TOOL

Assembly key for aluminium profile, Assembly key



SCE_SS

Stainless steel U-shaped clamp, Stainless steel



PT881

Drive sprocket for slat top chain, Range 881



CLLCLLP

Clevis components, long version, Steel - long range



G4-ECO

Eco range Spur gear, Steel C45



NTMdl

Set screw delrin tip, Delrin-point



CFUURSS

Cam follower stainless steel, Standard - stainless steel



TUBE25_25

Square Tube, Aluminium or Stainless steel



VDSCB


Sliding lock adjustment system, Blocking wedge for sliding lock for ...



PRF_PL_4590


Joining plate for aluminium profile, Joint plate - 45x90 mm

Complementary products

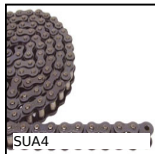

SUA4

Single chain supplied by the metre, Steel

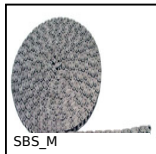

SBS_M

Single chain supplied by the metre, Stainless steel



PTR

Idle chain sprocket, For standard applications



PCS625S

Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)