

Chain sprocket **DIN 10B-1**



Pitch 5/8"

Steel

- Pitch 5/8" (15.875 mm) (DIN 10B-1)
- Roller diameter 10.16mm
- Material: Steel C43
- **We are unable to modify these parts**

Options


- American pitch (ASA) on request
- The prebore dimensions are given as a guide only and are subject to change
- **Custom made versions available**

Accessories

- SBR-625 and SBS-265 chains

Economy range

PCS

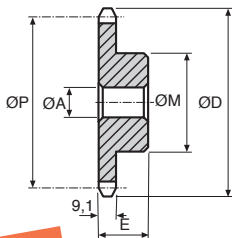

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP	ØD	ØM	ØA	E	Stock*	Price each 1 to 5
PCS62-8	8	41,48	47,0	25	10	25	✓	2,74 €
PCS62-9	9	46,42	52,6	30	10	25	-	3,77 €
PCS62-10	10	51,37	57,5	35	10	25	✓	3,77 €
PCS62-13	13	66,32	73,0	47	12	30	✓	6,98 €
PCS62-15	15	76,36	83,0	57	12	30	✓	8,63 €
PCS62-16	16	81,37	88,0	60	14	30	✓	9,62 €
PCS62-17	17	86,39	93,0	60	14	30	✓	10,34 €
PCS62-18	18	91,42	98,3	70	14	30	✓	11,57 €
PCS62-20	20	101,49	108,4	75	14	30	✓	13,41 €
PCS62-21	21	106,52	113,4	75	16	30	✓	14,45 €
PCS62-22	22	111,55	118,0	80	16	30	-	15,82 €
PCS62-23	23	116,58	123,4	80	16	30	-	16,60 €
PCS62-24	24	121,62	128,3	80	16	30	-	17,35 €
PCS62-25	25	126,66	134,0	80	16	30	-	18,01 €
PCS62-26	26	131,70	139,0	85	20	35	-	21,51 €
PCS62-27	27	136,75	144,0	85	20	35	-	23,29 €
PCS62-28	28	141,78	148,7	90	20	35	-	24,37 €
PCS62-29	29	146,83	153,8	90	20	35	-	25,81 €
PCS62-30	30	151,87	158,8	90	20	35	✓	26,57 €
PCS62-31	31	156,92	163,9	95	20	35	-	28,65 €
PCS62-32	32	161,95	168,9	95	20	35	-	29,72 €
PCS62-33	33	167,00	174,5	95	20	35	-	30,93 €
PCS62-34	34	172,05	179,0	95	20	35	-	31,89 €
PCS62-35	35	177,10	184,1	95	20	35	-	33,04 €
PCS62-38	38	192,24	199,2	100	20	35	-	37,57 €
PCS62-39	39	197,29	204,2	100	20	35	-	39,05 €
PCS62-40	40	202,34	209,3	100	20	35	✓	40,32 €

*Depending on availability - Dimensions in mm

Our other products



VCMB

Dual-thread screw
wood/metal, Steel



LVT

Miniature motorised
actuator 1A, 1 amper



AC156-157

Strike for toggle latch,
25.5mm



CHN_CHNSS

Straight long link
chain, Galvanised
steel



DOMI80

Connecting kits, XY
linking kit




TK

Topball self-aligning
linear bearing, Topball
self-aligning



TBD

Manual leadscrew
table with opposing
threads, 5kg

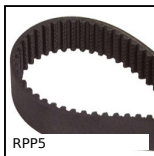

RPP5

RPP heavy duty
timing belt, RPP5



NT121

Spur gear coaxial
gearbox, from 20 to



EHD06

Internal epicyclic
servo reducers, from



SCA_SS

Stainless steel flat
cable clamp, Stainless



DIA


Ring operated locking
bolt, with ring

Complementary products



SUA4

 Single chain supplied
by the metre, Steel



SBS_M

Single chain supplied
by the metre,
Stainless steel



PTR

Idle chain sprocket,
For standard
applications



PCS625S

Chain sprocket -
Stainless steel,
15.875mm (DIN
08B-1)