

Chain sprocket with **hardened teeth**

DIN10B-1 5/8"

C45 tempered steel



2 threaded holes

- Pitch 15,875mm (DIN 10B-1)
- Roller diameter 10,16mm
- Materials:
C45 steel UNI7845
Hardened teeth 45-53HRC



Accessory

- SBR-625/M chain

Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

Bore and keyway

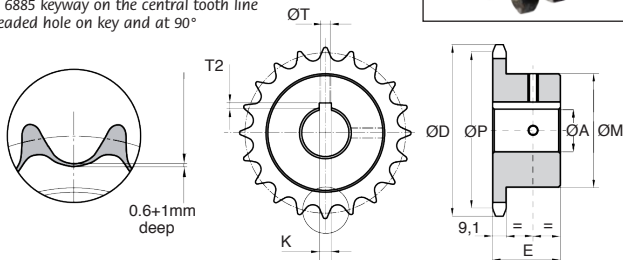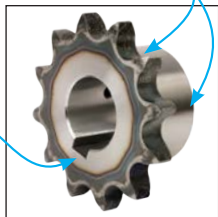

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each					
										1 to 5					
PCS62-12H-16K	12	61,34	68,20	42	30	16	5	2,30	M4	10,66 €					
PCS62-12H-19K						19	6	2,80	M5	10,66 €					
PCS62-12H-20K						20	6	2,80	M5	10,66 €					
PCS62-12H-22K						22	6	2,80	M5	10,66 €					
PCS62-12H-24K						24	8	3,30	M6	10,66 €					
PCS62-12H-25K						25	8	3,30	M6	10,66 €					
PCS62-12H-28K						51	30	28	8	3,30	M6	10,66 €			
PCS62-12H-30K						51	30	30	8	3,30	M6	10,66 €			
PCS62-13H-16K						13	66,32	73,20	47	30	16	5	2,30	M4	11,40 €
PCS62-13H-19K											19	6	2,80	M5	11,40 €
PCS62-13H-20K	20	6	2,80	M5	11,40 €										
PCS62-13H-22K	22	6	2,80	M5	11,40 €										
PCS62-13H-24K	24	8	3,30	M6	11,40 €										
PCS62-13H-25K	25	8	3,30	M6	11,40 €										
PCS62-13H-28K	28	8	3,30	M6	11,40 €										
PCS62-13H-30K	30	8	3,30	M6	11,40 €										

All dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each 1 à 5
PCS62-14H-16K						16	5	2,30	M4	12,26 €
PCS62-14H-19K						19	6	2,80	M5	12,26 €
PCS62-14H-20K						20	6	2,80	M5	12,26 €
PCS62-14H-22K						22	6	2,80	M5	12,26 €
PCS62-14H-24K	14	71,34	78,20	52	30	24	8	3,30	M6	12,26 €
PCS62-14H-25K						25	8	3,30	M6	12,26 €
PCS62-14H-28K						28	8	3,30	M6	12,26 €
PCS62-14H-30K						30	8	3,30	M6	12,26 €
PCS62-15H-19K						19	6	2,80	M5	13,73 €
PCS62-15H-20K						20	6	2,80	M5	13,73 €
PCS62-15H-22K						22	6	2,80	M5	13,73 €
PCS62-15H-24K						24	8	3,30	M6	13,73 €
PCS62-15H-25K	15	76,36	83,20	57	30	25	8	3,30	M6	13,73 €
PCS62-15H-28K						28	8	3,30	M6	13,73 €
PCS62-15H-30K						30	8	3,30	M6	13,73 €
PCS62-15H-32K						32	10	3,30	M8	13,73 €
PCS62-15H-35K						35	10	3,30	M8	13,73 €
PCS62-16H-20K						20	6	2,80	M5	14,55 €
PCS62-16H-22K						22	6	2,80	M5	14,55 €
PCS62-16H-24K						24	8	3,30	M6	14,55 €
PCS62-16H-25K	16	81,37	88,00	60	30	25	8	3,30	M6	14,55 €
PCS62-16H-28K						28	8	3,30	M6	14,55 €
PCS62-16H-30K						30	8	3,30	M6	14,55 €
PCS62-16H-32K						32	10	3,30	M8	14,55 €
PCS62-16H-35K						35	10	3,30	M8	14,55 €
PCS62-17H-20K						20	6	2,80	M5	15,90 €
PCS62-17H-22K						22	6	2,80	M5	15,90 €
PCS62-17H-24K						24	8	3,30	M6	15,90 €
PCS62-17H-25K	17	86,39	93,20	60	30	25	8	3,30	M6	15,90 €
PCS62-17H-28K						28	8	3,30	M6	15,90 €
PCS62-17H-30K						30	8	3,30	M6	15,90 €
PCS62-17H-32K						32	10	3,30	M8	15,90 €
PCS62-17H-35K						35	10	3,30	M8	15,90 €
PCS62-18H-20K						20	6	2,80	M5	17,70 €
PCS62-18H-22K						22	6	2,80	M5	17,70 €
PCS62-18H-24K						24	8	3,30	M6	17,70 €
PCS62-18H-25K						25	8	3,30	M6	17,70 €
PCS62-18H-28K	18	91,42	98,30	70	30	28	8	3,30	M6	17,70 €
PCS62-18H-30K						30	8	3,30	M6	17,70 €
PCS62-18H-32K						32	10	3,30	M8	17,70 €
PCS62-18H-35K						35	10	3,30	M8	17,70 €
PCS62-18H-38K						38	10	3,30	M8	17,70 €
PCS62-18H-40K						40	12	3,30	M10	17,70 €

Fax

0 825 88 6000

Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

305

Chain sprocket with **hardened teeth** **Ste DIN**

DIN10B-1
5/8"

C45 tempered steel



- Pitch 15,875mm (DIN 10B-1)
- Roller diameter 10,16mm
- Materials:
C45 steel UNI7845
Hardened teeth 45-53HRC

Accessory



- SBR-625/M chain

Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

2 threaded holes

Bore and keyway

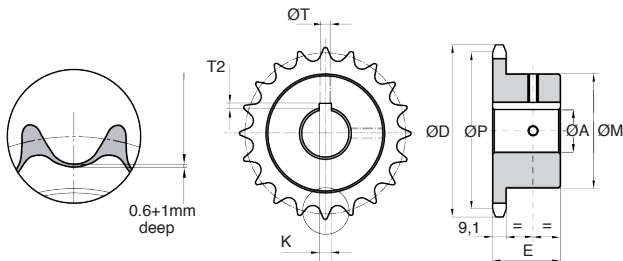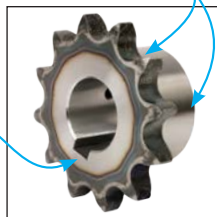

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA (H9)	K T2	ØT	Price each 1 to 5
PCS62-19H-20K						20	6	2,80 M5	19,13 €
PCS62-19H-22K						22	6	2,80 M5	19,13 €
PCS62-19H-24K						24	8	3,30 M6	19,13 €
PCS62-19H-25K						25	8	3,30 M6	19,13 €
PCS62-19H-28K						28	8	3,30 M6	19,13 €
PCS62-19H-30K	19	96,45	103,30	70	30	30	8	3,30 M6	19,13 €
PCS62-19H-32K						32	10	3,30 M8	19,13 €
PCS62-19H-35K						35	10	3,30 M8	19,13 €
PCS62-19H-38K						38	10	3,30 M8	19,13 €
PCS62-19H-40K						40	12	3,30 M10	19,13 €

All dimensions in mm

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each 1 to 5
PCS62-20H-20K	20	101,49	108,40	75	30	20	6	2,80	M5	21,09 €
PCS62-20H-22K						22	6	2,80	M5	21,09 €
PCS62-20H-24K						24	8	3,30	M6	21,09 €
PCS62-20H-25K						25	8	3,30	M6	21,09 €
PCS62-20H-28K						28	8	3,30	M6	21,09 €
PCS62-20H-30K						30	8	3,30	M6	21,09 €
PCS62-20H-32K						32	10	3,30	M8	21,09 €
PCS62-20H-35K						35	10	3,30	M8	21,09 €
PCS62-20H-38K						38	10	3,30	M8	21,09 €
PCS62-20H-40K						40	12	3,30	M10	21,09 €
PCS62-21H-20K	21	106,52	113,40	75	30	20	6	2,80	M5	22,27 €
PCS62-21H-22K						22	6	2,80	M5	22,27 €
PCS62-21H-24K						24	8	3,30	M6	22,27 €
PCS62-21H-25K						25	8	3,30	M6	22,27 €
PCS62-21H-28K						28	8	3,30	M6	22,27 €
PCS62-21H-30K						30	8	3,30	M6	22,27 €
PCS62-21H-32K						32	10	3,30	M8	22,27 €
PCS62-21H-35K						35	10	3,30	M8	22,27 €
PCS62-21H-38K						38	10	3,30	M8	22,27 €
PCS62-21H-40K						40	12	3,30	M10	22,27 €
PCS62-23H-20K	23	116,58	123,40	80	30	20	6	2,80	M5	25,46 €
PCS62-23H-22K						22	6	2,80	M5	25,46 €
PCS62-23H-24K						24	8	3,30	M6	25,46 €
PCS62-23H-25K						25	8	3,30	M6	25,46 €
PCS62-23H-28K						28	8	3,30	M6	25,46 €
PCS62-23H-30K						30	8	3,30	M6	25,46 €
PCS62-23H-32K						32	10	3,30	M8	25,46 €
PCS62-23H-35K						35	10	3,30	M8	25,46 €
PCS62-23H-38K						38	10	3,30	M8	25,46 €
PCS62-23H-40K						40	12	3,30	M10	25,46 €
PCS62-23H-42K	42	12	3,30	M10	25,46 €					
PCS62-24H-20K	24	121,62	128,50	80	30	20	6	2,80	M5	26,77 €
PCS62-24H-22K						22	6	2,80	M5	26,77 €
PCS62-24H-24K						24	8	3,30	M6	26,77 €
PCS62-24H-25K						25	8	3,30	M6	26,77 €
PCS62-24H-28K						28	8	3,30	M6	26,77 €
PCS62-24H-30K						30	8	3,30	M6	26,77 €
PCS62-24H-32K						32	10	3,30	M8	26,77 €
PCS62-24H-35K						35	10	3,30	M8	26,77 €
PCS62-24H-38K						38	10	3,30	M8	26,77 €
PCS62-24H-40K						40	12	3,30	M10	26,77 €
PCS62-24H-42K	42	12	3,30	M10	26,77 €					
PCS62-25H-22K	25	126,66	133,50	80	30	22	6	2,80	M5	27,71 €
PCS62-25H-24K						24	8	3,30	M6	27,71 €
PCS62-25H-25K						25	8	3,30	M6	27,71 €
PCS62-25H-28K						28	8	3,30	M6	27,71 €
PCS62-25H-30K						30	8	3,30	M6	27,71 €
PCS62-25H-32K						32	10	3,30	M8	27,71 €
PCS62-25H-35K						35	10	3,30	M8	27,71 €
PCS62-25H-38K						38	10	3,30	M8	27,71 €
PCS62-25H-40K						40	12	3,30	M10	27,71 €
PCS62-25H-42K						42	12	3,30	M10	27,71 €

Our other products



VAB

Flanged nut for ball screw, For VAB ballscrew



CAP805

Slat top chain stainless steel, Large range 805



PRF-SCL

Lock for aluminium profile, Lock for sliding doors



SH0

Parallel axis helical gear, Steel 20NCD2



PRF-GUM

Aluminium profile anodising polisher, Polishing block




PT820

Drive sprocket for slat top chain, Ranges 820 and 815



T10courroie

 T type timing belt, T10 Steel cored polyurethane



RPP14

RPP heavy duty timing belt, RPP14



 
GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



GLT2-27

Telescopic drawer runners for groove mounting, Partial



CHTRP

Single and dual output gearboxes, Up to 34,5 Nm

Complementary products



SUA4

Single chain supplied by the metre, Steel



SUA4_L

Chain link, Steel



PCS62

Chain sprocket - steel, 15.875 (DIN 10B-1)



PCS62SS

Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)