

Chain sprocket with **hardened teeth**

DIN10B-1 5/8"

C45 tempered steel



2 threaded holes

- Pitch 15,875mm (DIN 10B-1)
- Roller diameter 10,16mm
- Materials:
C45 steel UNI7845
Hardened teeth 45-53HRC



Accessory

- SBR-625/M chain

Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

Bore and keyway

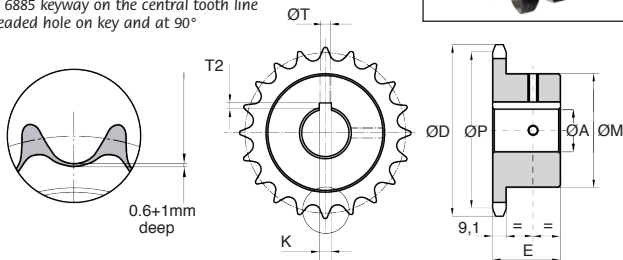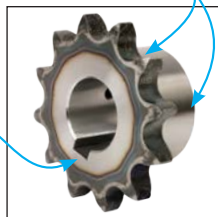

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each					
										1 to 5					
PCS62-12H-16K	12	61,34	68,20	42	30	16	5	2,30	M4	10,66 €					
PCS62-12H-19K						19	6	2,80	M5	10,66 €					
PCS62-12H-20K						20	6	2,80	M5	10,66 €					
PCS62-12H-22K						22	6	2,80	M5	10,66 €					
PCS62-12H-24K						24	8	3,30	M6	10,66 €					
PCS62-12H-25K						25	8	3,30	M6	10,66 €					
PCS62-12H-28K						51	30	28	8	3,30	M6	10,66 €			
PCS62-12H-30K						51	30	30	8	3,30	M6	10,66 €			
PCS62-13H-16K						13	66,32	73,20	47	30	16	5	2,30	M4	11,40 €
PCS62-13H-19K											19	6	2,80	M5	11,40 €
PCS62-13H-20K	20	6	2,80	M5	11,40 €										
PCS62-13H-22K	22	6	2,80	M5	11,40 €										
PCS62-13H-24K	24	8	3,30	M6	11,40 €										
PCS62-13H-25K	25	8	3,30	M6	11,40 €										
PCS62-13H-28K	28	8	3,30	M6	11,40 €										
PCS62-13H-30K	30	8	3,30	M6	11,40 €										

All dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each 1 à 5
PCS62-14H-16K						16	5	2,30	M4	12,26 €
PCS62-14H-19K						19	6	2,80	M5	12,26 €
PCS62-14H-20K						20	6	2,80	M5	12,26 €
PCS62-14H-22K						22	6	2,80	M5	12,26 €
PCS62-14H-24K	14	71,34	78,20	52	30	24	8	3,30	M6	12,26 €
PCS62-14H-25K						25	8	3,30	M6	12,26 €
PCS62-14H-28K						28	8	3,30	M6	12,26 €
PCS62-14H-30K						30	8	3,30	M6	12,26 €
PCS62-15H-19K						19	6	2,80	M5	13,73 €
PCS62-15H-20K						20	6	2,80	M5	13,73 €
PCS62-15H-22K						22	6	2,80	M5	13,73 €
PCS62-15H-24K						24	8	3,30	M6	13,73 €
PCS62-15H-25K	15	76,36	83,20	57	30	25	8	3,30	M6	13,73 €
PCS62-15H-28K						28	8	3,30	M6	13,73 €
PCS62-15H-30K						30	8	3,30	M6	13,73 €
PCS62-15H-32K						32	10	3,30	M8	13,73 €
PCS62-15H-35K						35	10	3,30	M8	13,73 €
PCS62-16H-20K						20	6	2,80	M5	14,55 €
PCS62-16H-22K						22	6	2,80	M5	14,55 €
PCS62-16H-24K						24	8	3,30	M6	14,55 €
PCS62-16H-25K	16	81,37	88,00	60	30	25	8	3,30	M6	14,55 €
PCS62-16H-28K						28	8	3,30	M6	14,55 €
PCS62-16H-30K						30	8	3,30	M6	14,55 €
PCS62-16H-32K						32	10	3,30	M8	14,55 €
PCS62-16H-35K						35	10	3,30	M8	14,55 €
PCS62-17H-20K						20	6	2,80	M5	15,90 €
PCS62-17H-22K						22	6	2,80	M5	15,90 €
PCS62-17H-24K						24	8	3,30	M6	15,90 €
PCS62-17H-25K	17	86,39	93,20	60	30	25	8	3,30	M6	15,90 €
PCS62-17H-28K						28	8	3,30	M6	15,90 €
PCS62-17H-30K						30	8	3,30	M6	15,90 €
PCS62-17H-32K						32	10	3,30	M8	15,90 €
PCS62-17H-35K						35	10	3,30	M8	15,90 €
PCS62-18H-20K						20	6	2,80	M5	17,70 €
PCS62-18H-22K						22	6	2,80	M5	17,70 €
PCS62-18H-24K						24	8	3,30	M6	17,70 €
PCS62-18H-25K						25	8	3,30	M6	17,70 €
PCS62-18H-28K	18	91,42	98,30	70	30	28	8	3,30	M6	17,70 €
PCS62-18H-30K						30	8	3,30	M6	17,70 €
PCS62-18H-32K						32	10	3,30	M8	17,70 €
PCS62-18H-35K						35	10	3,30	M8	17,70 €
PCS62-18H-38K						38	10	3,30	M8	17,70 €
PCS62-18H-40K						40	12	3,30	M10	17,70 €

Fax

0 825 88 6000
Service 0,15 €/min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

305

Chain sprocket with **hardened teeth** **Ste DIN**

DIN10B-1
5/8"

C45 tempered steel



- Pitch 15,875mm (DIN 10B-1)
- Roller diameter 10,16mm
- Materials:
C45 steel UNI7845
Hardened teeth 45-53HRC

Accessory



- SBR-625/M chain

Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

2 threaded holes

Bore and keyway

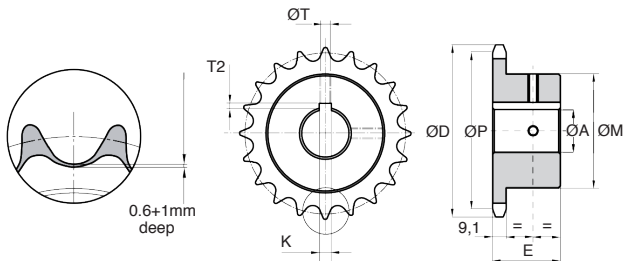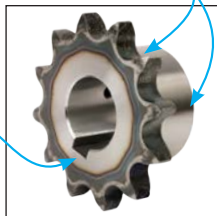

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA (H9)	K (H9)	T2	ØT	Price each 1 to 5
PCS62-19H-20K						20	6	2,80	M5	19,13 €
PCS62-19H-22K						22	6	2,80	M5	19,13 €
PCS62-19H-24K						24	8	3,30	M6	19,13 €
PCS62-19H-25K						25	8	3,30	M6	19,13 €
PCS62-19H-28K						28	8	3,30	M6	19,13 €
PCS62-19H-30K	19	96,45	103,30	70	30	30	8	3,30	M6	19,13 €
PCS62-19H-32K						32	10	3,30	M8	19,13 €
PCS62-19H-35K						35	10	3,30	M8	19,13 €
PCS62-19H-38K						38	10	3,30	M8	19,13 €
PCS62-19H-40K						40	12	3,30	M10	19,13 €

All dimensions in mm

Part N°	Z					K				Price each 1 to 5					
	Teeth	ØP	ØD	ØM	E	ØA	(H9)	T2	ØT						
PCS62-20H-20K	20	101,49	108,40	75	30	20	6	2,80	M5	21,09 €					
PCS62-20H-22K						22	6	2,80	M5	21,09 €					
PCS62-20H-24K						24	8	3,30	M6	21,09 €					
PCS62-20H-25K						25	8	3,30	M6	21,09 €					
PCS62-20H-28K						28	8	3,30	M6	21,09 €					
PCS62-20H-30K						30	8	3,30	M6	21,09 €					
PCS62-20H-32K						32	10	3,30	M8	21,09 €					
PCS62-20H-35K						35	10	3,30	M8	21,09 €					
PCS62-20H-38K						38	10	3,30	M8	21,09 €					
PCS62-20H-40K						40	12	3,30	M10	21,09 €					
PCS62-21H-20K						21	106,52	113,40	75	30	20	6	2,80	M5	22,27 €
PCS62-21H-22K											22	6	2,80	M5	22,27 €
PCS62-21H-24K	24	8	3,30	M6	22,27 €										
PCS62-21H-25K	25	8	3,30	M6	22,27 €										
PCS62-21H-28K	28	8	3,30	M6	22,27 €										
PCS62-21H-30K	30	8	3,30	M6	22,27 €										
PCS62-21H-32K	32	10	3,30	M8	22,27 €										
PCS62-21H-35K	35	10	3,30	M8	22,27 €										
PCS62-21H-38K	38	10	3,30	M8	22,27 €										
PCS62-21H-40K	40	12	3,30	M10	22,27 €										
PCS62-23H-20K	23	116,58	123,40	80	30						20	6	2,80	M5	25,46 €
PCS62-23H-22K											22	6	2,80	M5	25,46 €
PCS62-23H-24K						24	8	3,30	M6	25,46 €					
PCS62-23H-25K						25	8	3,30	M6	25,46 €					
PCS62-23H-28K						28	8	3,30	M6	25,46 €					
PCS62-23H-30K						30	8	3,30	M6	25,46 €					
PCS62-23H-32K						32	10	3,30	M8	25,46 €					
PCS62-23H-35K						35	10	3,30	M8	25,46 €					
PCS62-23H-38K						38	10	3,30	M8	25,46 €					
PCS62-23H-40K						40	12	3,30	M10	25,46 €					
PCS62-23H-42K						42	12	3,30	M10	25,46 €					
PCS62-24H-20K						24	121,62	128,50	80	30	20	6	2,80	M5	26,77 €
PCS62-24H-22K	22	6	2,80	M5	26,77 €										
PCS62-24H-24K	24	8	3,30	M6	26,77 €										
PCS62-24H-25K	25	8	3,30	M6	26,77 €										
PCS62-24H-28K	28	8	3,30	M6	26,77 €										
PCS62-24H-30K	30	8	3,30	M6	26,77 €										
PCS62-24H-32K	32	10	3,30	M8	26,77 €										
PCS62-24H-35K	35	10	3,30	M8	26,77 €										
PCS62-24H-38K	38	10	3,30	M8	26,77 €										
PCS62-24H-40K	40	12	3,30	M10	26,77 €										
PCS62-24H-42K	42	12	3,30	M10	26,77 €										
PCS62-25H-22K	25	126,66	133,50	80	30						22	6	2,80	M5	27,71 €
PCS62-25H-24K						24	8	3,30	M6	27,71 €					
PCS62-25H-25K						25	8	3,30	M6	27,71 €					
PCS62-25H-28K						28	8	3,30	M6	27,71 €					
PCS62-25H-30K						30	8	3,30	M6	27,71 €					
PCS62-25H-32K						32	10	3,30	M8	27,71 €					
PCS62-25H-35K						35	10	3,30	M8	27,71 €					
PCS62-25H-38K						38	10	3,30	M8	27,71 €					
PCS62-25H-40K						40	12	3,30	M10	27,71 €					
PCS62-25H-42K						42	12	3,30	M10	27,71 €					

 
Our other products



ADL
Eye bolt high resistance, alloy steel



EBG
Cap nut Hygienic Design®, Compact



RPP
Connecting plate for RPP type timing belts, RRP5



UGH16
H Type Guide units, For Ø12 and Ø16 actuators



CHINV2
Invisible hinge, Invisible - Opening up to 125°



 
OP3_14_06
Reducing sleeve for OP indicators, Reduction socket




CFE
Female rod ends DIN ISO12240-4, Steel / bronze



H0
Crossed helical gear crossed axis at 90°, Steel 20NCD2



 RPPM
RPP type belt per metre, RPP5 Steel cored polyurethane



PM3
Worm, Machined plastic (delrin)



LF
Precision locknut, Precision locknut



CHML50
Worm and wheel gear reducer, up to 107 Nm - Integrated torque limiter

Complementary products



SUA4
Single chain supplied by the metre, Steel



SUA4_L
Chain link, Steel



PCS62
Chain sprocket - steel, 15.875 (DIN 10B-1)



PCS62SS
Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)