


C45 steel

Pitch 6mm

- Pitch 6mm (DIN 04-1)
- Roller diameter 4mm
- Material:
C45 UNI7845 steel
- HPC are unable to modify these parts
- **The prebore dimensions are given as a guide only and are subject to change

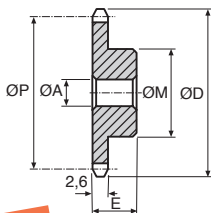

Accessories

- Chain part number SUA-6/M

Economy range

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS6-10	10	19,42	21,70	13	6	10	0,01	1,37 €
PCS6-11	11	21,30	23,60	14	6	10	0,01	1,47 €
PCS6-12	12	23,18	25,40	16	6	10	0,02	2,14 €
PCS6-13	13	25,05	27,30	18	8	10	0,02	2,48 €
PCS6-14	14	26,96	29,20	20	8	10	0,03	2,48 €
PCS6-15	15	28,86	31,00	20	8	10	0,03	2,48 €
PCS6-16	16	30,76	33,00	20	8	13	0,03	2,86 €
PCS6-17	17	32,65	35,00	20	8	13	0,04	3,40 €
PCS6-18	18	34,55	36,90	20	8	13	0,04	3,40 €
PCS6-19	19	36,44	38,80	20	8	13	0,04	3,48 €
PCS6-20	20	38,34	40,70	20	8	13	0,04	3,61 €
PCS6-21	21	40,25	42,60	25	8	13	0,06	3,91 €
PCS6-22	22	42,16	44,50	25	8	13	0,06	4,33 €
PCS6-23	23	44,06	46,40	25	8	13	0,06	4,53 €
PCS6-24	24	45,96	48,30	25	8	13	0,07	4,62 €
PCS6-25	25	47,87	50,20	25	8	13	0,07	5,30 €
PCS6-27	27	51,67	54,00	30	8	15	0,10	5,80 €
PCS6-30	30	57,42	59,80	30	8	15	0,11	7,49 €
PCS6-33	33	63,11	65,50	30	8	15	0,12	8,12 €
PCS6-35	35	66,93	69,30	30	8	15	0,13	8,28 €
PCS6-36	36	68,84	71,20	30	8	15	0,13	8,96 €
PCS6-38	38	72,66	75,00	30	8	15	0,14	9,34 €
PCS6-40	40	76,47	78,90	30	8	15	0,15	10,31 €
PCS6-45	45	86,01	88,50	40	10	16	0,46	12,83 €
PCS6-48	48	91,74	94,20	62	12	18	0,48	13,25 €
PCS6-50	50	95,55	98,00	50	12	20	0,49	13,42 €
PCS6-57	57	108,93	111,40	50	12	20	0,53	14,14 €
PCS6-76	76	145,19	147,60	60	12	20	1,58	29,25 €

Dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

293

Our other products



Locking rings in stainless steel, Stainless steel



Single row cylindrical roller bearing, Free inner ring



Lead screw clamping collar, Aluminium



3-spoked handwheel with foldable handle, Polyamide



Articulated levelling foot, pressed base Ø80, Ø 80



Machined plastic bevel gear, 1:1



Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



V shaped channel UtiliTrak®, V rail



Worm and wheel set, Unhardened steel



Hinge without pin, Plastic hinge



Telescopic drawer,



Right angled gearbox, bored shafts, up to 70 Nm

Complementary products



Single chain supplied by the metre, Steel



Chain link, Steel