


C45 steel

 Pitch  
**6mm**

- Pitch 6mm (DIN 04-1)
- Roller diameter 4mm
- Material:  
C45 UNI7845 steel
- HPC are unable to modify these parts
- \*\*The prebore dimensions are given as a guide only and are subject to change

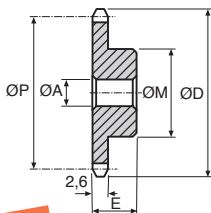

## Accessories

- Chain part number SUA-6/M

**Economy range**

## DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS6-10	10	19,42	21,70	13	6	10	0,01	1,37 €
PCS6-11	11	21,30	23,60	14	6	10	0,01	1,47 €
PCS6-12	12	23,18	25,40	16	6	10	0,02	2,14 €
PCS6-13	13	25,05	27,30	18	8	10	0,02	2,48 €
PCS6-14	14	26,96	29,20	20	8	10	0,03	2,48 €
PCS6-15	15	28,86	31,00	20	8	10	0,03	2,48 €
PCS6-16	16	30,76	33,00	20	8	13	0,03	2,86 €
PCS6-17	17	32,65	35,00	20	8	13	0,04	3,40 €
PCS6-18	18	34,55	36,90	20	8	13	0,04	3,40 €
PCS6-19	19	36,44	38,80	20	8	13	0,04	3,48 €
PCS6-20	20	38,34	40,70	20	8	13	0,04	3,61 €
PCS6-21	21	40,25	42,60	25	8	13	0,06	3,91 €
PCS6-22	22	42,16	44,50	25	8	13	0,06	4,33 €
PCS6-23	23	44,06	46,40	25	8	13	0,06	4,53 €
PCS6-24	24	45,96	48,30	25	8	13	0,07	4,62 €
PCS6-25	25	47,87	50,20	25	8	13	0,07	5,30 €
PCS6-27	27	51,67	54,00	30	8	15	0,10	5,80 €
PCS6-30	30	57,42	59,80	30	8	15	0,11	7,49 €
PCS6-33	33	63,11	65,50	30	8	15	0,12	8,12 €
PCS6-35	35	66,93	69,30	30	8	15	0,13	8,28 €
PCS6-36	36	68,84	71,20	30	8	15	0,13	8,96 €
PCS6-38	38	72,66	75,00	30	8	15	0,14	9,34 €
PCS6-40	40	76,47	78,90	30	8	15	0,15	10,31 €
PCS6-45	45	86,01	88,50	40	10	16	0,46	12,83 €
PCS6-48	48	91,74	94,20	62	12	18	0,48	13,25 €
PCS6-50	50	95,55	98,00	50	12	20	0,49	13,42 €
PCS6-57	57	108,93	111,40	50	12	20	0,53	14,14 €
PCS6-76	76	145,19	147,60	60	12	20	1,58	29,25 €

Dimensions in mm

**0 825 88 6000**

Service 0,15 € / min  
+ prix appel

Fax

## Our other products



HLC19

Right angle spiro bevel gearbox, Up to 43Nm



DCG

Suction cup, 2.5 bellows, nitrile



BPH

Ball transfer unit plain fit, High




NT91

Spur gear coaxial gearbox, from 10 to 35 Nm - In-line



GTC

 Belt tensioner, For standard applications



EPRF

High helix leadscrew, Flanged nut - up to 40mm per rotation



M0

Worm and wheel set, Bronze



TBE16

Economic mini-table with trapezoidal leadscrew, 5kg



PNA\_R

PERIFLEX elastic coupling,



 
SLBW

Indexing plunger, weldable, Weldable -



MFBC

Flexible Bellows coupling, Aluminium



TBV

Manual lifting tables, 12kg

## Complementary products



SUA4

Single chain supplied by the metre, Steel



SUA4\_L

Chain link, Steel