


C45 steel

Pitch 6mm

- Pitch 6mm (DIN 04-1)
- Roller diameter 4mm
- Material:
C45 UNI7845 steel
- HPC are unable to modify these parts
- **The prebore dimensions are given as a guide only and are subject to change

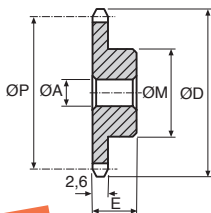

Accessories

- Chain part number SUA-6/M

Economy range

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS6-10	10	19,42	21,70	13	6	10	0,01	1,37 €
PCS6-11	11	21,30	23,60	14	6	10	0,01	1,47 €
PCS6-12	12	23,18	25,40	16	6	10	0,02	2,14 €
PCS6-13	13	25,05	27,30	18	8	10	0,02	2,48 €
PCS6-14	14	26,96	29,20	20	8	10	0,03	2,48 €
PCS6-15	15	28,86	31,00	20	8	10	0,03	2,48 €
PCS6-16	16	30,76	33,00	20	8	13	0,03	2,86 €
PCS6-17	17	32,65	35,00	20	8	13	0,04	3,40 €
PCS6-18	18	34,55	36,90	20	8	13	0,04	3,40 €
PCS6-19	19	36,44	38,80	20	8	13	0,04	3,48 €
PCS6-20	20	38,34	40,70	20	8	13	0,04	3,61 €
PCS6-21	21	40,25	42,60	25	8	13	0,06	3,91 €
PCS6-22	22	42,16	44,50	25	8	13	0,06	4,33 €
PCS6-23	23	44,06	46,40	25	8	13	0,06	4,53 €
PCS6-24	24	45,96	48,30	25	8	13	0,07	4,62 €
PCS6-25	25	47,87	50,20	25	8	13	0,07	5,30 €
PCS6-27	27	51,67	54,00	30	8	15	0,10	5,80 €
PCS6-30	30	57,42	59,80	30	8	15	0,11	7,49 €
PCS6-33	33	63,11	65,50	30	8	15	0,12	8,12 €
PCS6-35	35	66,93	69,30	30	8	15	0,13	8,28 €
PCS6-36	36	68,84	71,20	30	8	15	0,13	8,96 €
PCS6-38	38	72,66	75,00	30	8	15	0,14	9,34 €
PCS6-40	40	76,47	78,90	30	8	15	0,15	10,31 €
PCS6-45	45	86,01	88,50	40	10	16	0,46	12,83 €
PCS6-48	48	91,74	94,20	62	12	18	0,48	13,25 €
PCS6-50	50	95,55	98,00	50	12	20	0,49	13,42 €
PCS6-57	57	108,93	111,40	50	12	20	0,53	14,14 €
PCS6-76	76	145,19	147,60	60	12	20	1,58	29,25 €

Dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

Our other products




CHMR75

Worm and wheel gear reducer, up to 298 Nm



PAL

Self locking counter nut, For axial locking

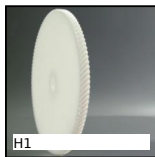


H1

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



RHTplss

 High Temperature Castor, up to 200kg



RPP3

RPP heavy duty timing belt, RPP3



CHMR63

Worm and wheel gear reducer, up to 196 Nm



 
TCLar

Automatic chain tensioner, With wide guide



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



KS

Keysteel, Stainless steel - Keystock



SSB

Stainless steel bevel gear, 1:1



BTC

End cap for square tube, Standard



PM2

Worm and wheel set, Hardened steel

Complementary products



SUA4

Single chain supplied by the metre, Steel



SUA4_L

Chain link, Steel