

Chain sprocket with **hardened teeth**

DIN12B-1
3/4"

C45 tempered steel



2 threaded holes

- Pitch 19,05mm (DIN 12B-1)
- Roller diameter 12,07mm
- Materials:
C45 steel UNI7845
Hardened teeth 45-53HRC



Accessory

- SBR-750/M chain

Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

Bore and keyway

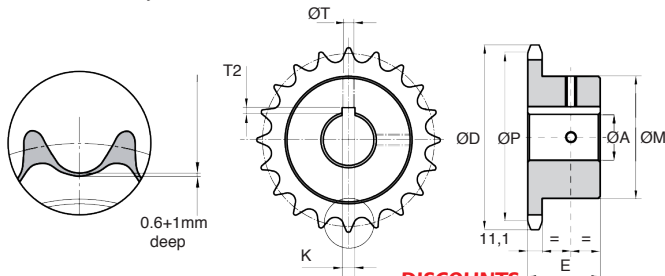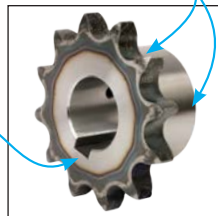

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each
										1 to 5
PCS75-12H-20K	12	73,60	81,80	52	35	20	6	2,80	M5	14,47 €
PCS75-12H-22K										14,47 €
PCS75-12H-24K										14,47 €
PCS75-12H-25K										14,47 €
PCS75-12H-28K										14,47 €
PCS75-12H-30K										14,47 €
PCS75-13H-20K	13	79,60	87,10	58	35	20	6	2,80	M5	16,06 €
PCS75-13H-22K										16,06 €
PCS75-13H-24K										16,06 €
PCS75-13H-25K										16,06 €
PCS75-13H-28K										16,06 €
PCS75-13H-30K										16,06 €
PCS75-13H-32K										16,06 €
PCS75-13H-35K										16,06 €

All dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z					K				Price each 1 to 5					
	Teeth	ØP	ØD	ØM	E	ØA	(H9)	T2	ØT						
PCS75-14H-20K	14	85,61	93,80	64	35	20	6	2,80	M5	17,61 €					
PCS75-14H-22K						22	6	2,80	M5	17,61 €					
PCS75-14H-24K						24	8	3,30	M6	17,61 €					
PCS75-14H-25K						25	8	3,30	M6	17,61 €					
PCS75-14H-28K						28	8	3,30	M6	17,61 €					
PCS75-14H-30K						30	8	3,30	M6	17,61 €					
PCS75-14H-32K						32	10	3,30	M8	17,61 €					
PCS75-14H-35K						35	10	3,30	M8	17,61 €					
PCS75-15H-20K						15	91,63	99,20	70	35	20	6	2,80	M5	20,07 €
PCS75-15H-22K											22	6	2,80	M5	20,07 €
PCS75-15H-24K	24	8	3,30	M6	20,07 €										
PCS75-15H-25K	25	8	3,30	M6	20,07 €										
PCS75-15H-28K	28	8	3,30	M6	20,07 €										
PCS75-15H-30K	30	8	3,30	M6	20,07 €										
PCS75-15H-32K	32	10	3,30	M8	20,07 €										
PCS75-15H-35K	35	10	3,30	M8	20,07 €										
PCS75-15H-38K	38	10	3,30	M8	20,07 €										
PCS75-15H-40K	40	12	3,30	M10	20,07 €										
PCS75-16H-20K	16	97,65	105,50	75	35	20	6	2,80	M5	22,60 €					
PCS75-16H-22K						22	6	2,80	M5	22,60 €					
PCS75-16H-24K						24	8	3,30	M6	22,60 €					
PCS75-16H-25K						25	8	3,30	M6	22,60 €					
PCS75-16H-28K						28	8	3,30	M6	22,60 €					
PCS75-16H-30K						30	8	3,30	M6	22,60 €					
PCS75-16H-32K						32	10	3,30	M8	22,60 €					
PCS75-16H-35K						35	10	3,30	M8	22,60 €					
PCS75-16H-38K						38	10	3,30	M8	22,60 €					
PCS75-16H-40K						40	12	3,30	M10	22,60 €					
PCS75-17H-22K	17	103,67	111,20	80	35	22	6	2,80	M5	24,97 €					
PCS75-17H-24K						24	8	3,30	M6	24,97 €					
PCS75-17H-25K						25	8	3,30	M6	24,97 €					
PCS75-17H-28K						28	8	3,30	M6	24,97 €					
PCS75-17H-30K						30	8	3,30	M6	24,97 €					
PCS75-17H-32K						32	10	3,30	M8	24,97 €					
PCS75-17H-35K						35	10	3,30	M8	24,97 €					
PCS75-17H-38K						38	10	3,30	M8	24,97 €					
PCS75-17H-40K						40	12	3,30	M10	24,97 €					
PCS75-18H-22K						18	109,71	118,00	80	35	22	6	2,80	M5	26,89 €
PCS75-18H-24K	24	8	3,30	M6	26,89 €										
PCS75-18H-25K	25	8	3,30	M6	26,89 €										
PCS75-18H-28K	28	8	3,30	M6	26,89 €										
PCS75-18H-30K	30	8	3,30	M6	26,89 €										
PCS75-18H-32K	32	10	3,30	M8	26,89 €										
PCS75-18H-35K	35	10	3,30	M8	26,89 €										
PCS75-18H-38K	38	10	3,30	M8	26,89 €										
PCS75-18H-40K	40	12	3,30	M10	26,89 €										

Fax

0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

309

Chain sprocket with **hardened teeth**

DIN12B-1 3/4"

C45 tempered steel



2 threaded holes

- Pitch 19,05mm (DIN 12B-1)
- Roller diameter 12,07mm
- Materials:
C45 steel UNI7845
Hardened teeth 45-53HRC





Accessory

- SBR-750/M chain

Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

Bore and keyway

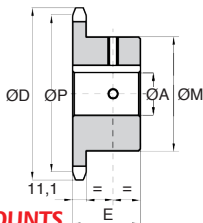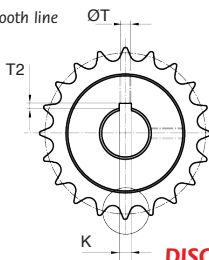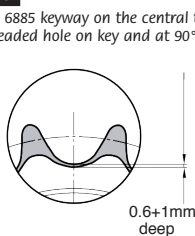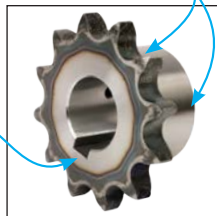

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each 1 to 5
PCS75-19H-25K	19	115,75	123,30	80	35	25	8	3,30	M6	29,31 €
PCS75-19H-28K						28	8	3,30	M6	29,31 €
PCS75-19H-30K						30	8	3,30	M6	29,31 €
PCS75-19H-32K						32	10	3,30	M8	29,31 €
PCS75-19H-35K						35	10	3,30	M8	29,31 €
PCS75-19H-38K						38	10	3,30	M8	29,31 €
PCS75-19H-40K						40	12	3,30	M10	29,31 €
PCS75-19H-42K						42	12	3,30	M10	29,31 €
PCS75-19H-45K						45	14	3,80	M12	29,31 €
PCS75-20H-25K						20	121,78	129,70	80	35
PCS75-20H-28K	28	8	3,30	M6	30,94 €					
PCS75-20H-30K	30	8	3,30	M6	30,94 €					
PCS75-20H-32K	32	10	3,30	M8	30,94 €					
PCS75-20H-35K	35	10	3,30	M8	30,94 €					
PCS75-20H-38K	38	10	3,30	M8	30,94 €					
PCS75-20H-40K	40	12	3,30	M10	30,94 €					
PCS75-20H-42K	42	12	3,30	M10	30,94 €					
PCS75-20H-45K	45	14	3,80	M12	30,94 €					

All dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z					K				Price each 1 t5
	Teeth	ØP	ØD	ØM	E	ØA	(H9)	T2	ØT	
PCS75-21H-28K	21	127,82	135,40	90	40	28	8	3,30	M6	36,62 €
PCS75-21H-30K						30	8	3,30	M6	36,62 €
PCS75-21H-32K						32	10	3,30	M8	36,62 €
PCS75-21H-35K						35	10	3,30	M8	36,62 €
PCS75-21H-38K						38	10	3,30	M8	36,62 €
PCS75-21H-40K						40	12	3,30	M10	36,62 €
PCS75-21H-42K						42	12	3,30	M10	36,62 €
PCS75-21H-45K						45	14	3,80	M12	36,62 €
PCS75-21H-48K						48	14	3,80	M12	36,62 €
PCS75-21H-50K						50	14	3,80	M12	36,62 €
PCS75-23H-28K	23	139,90	147,40	90	40	28	8	3,30	M6	41,04 €
PCS75-23H-30K						30	8	3,30	M6	41,04 €
PCS75-23H-32K						32	10	3,30	M8	41,04 €
PCS75-23H-35K						35	10	3,30	M8	41,04 €
PCS75-23H-38K						38	10	3,30	M8	41,04 €
PCS75-23H-40K						40	12	3,30	M10	41,04 €
PCS75-23H-42K						42	12	3,30	M10	41,04 €
PCS75-23H-45K						45	14	3,80	M12	41,04 €
PCS75-23H-48K						48	14	3,80	M12	41,04 €
PCS75-23H-50K						50	14	3,80	M12	41,04 €
PCS75-24H-28K	24	145,94	154,10	90	40	28	8	3,30	M6	42,39 €
PCS75-24H-30K						30	8	3,30	M6	42,39 €
PCS75-24H-32K						32	10	3,30	M8	42,39 €
PCS75-24H-35K						35	10	3,30	M8	42,39 €
PCS75-24H-38K						38	10	3,30	M8	42,39 €
PCS75-24H-40K						40	12	3,30	M10	42,39 €
PCS75-24H-42K						42	12	3,30	M10	42,39 €
PCS75-24H-45K						45	14	3,80	M12	42,39 €
PCS75-24H-48K						48	14	3,80	M12	42,39 €
PCS75-24H-50K						50	14	3,80	M12	42,39 €
PCS75-25H-28K	25	152,00	159,50	90	40	28	8	3,30	M6	44,96 €
PCS75-25H-30K						30	8	3,30	M6	44,96 €
PCS75-25H-32K						32	10	3,30	M8	44,96 €
PCS75-25H-35K						35	10	3,30	M8	44,96 €
PCS75-25H-38K						38	10	3,30	M8	44,96 €
PCS75-25H-40K						40	12	3,30	M10	44,96 €
PCS75-25H-42K						42	12	3,30	M10	44,96 €
PCS75-25H-45K						45	14	3,80	M12	44,96 €
PCS75-25H-48K						48	14	3,80	M12	44,96 €
PCS75-25H-50K						50	14	3,80	M12	44,96 €

Our other products



BUT

Panel stop, Panel stop



GGB

Female wing knob,
With blind thread



RTE

Rotex®, jaw coupling,
steel



DB

Steel bevel gear, 2:1



RDCss

Rigging screw with 2
jaws stainless steel,
Stainless steel



PM3

Worm and wheel set,
Hardened steel



GMK17_R

Round guide, Round
guide for conical
profile



SBF

Sealed flange bearing
unit for Food Industry,
cover



Brush strip per meter
PA6 fibres Ø0.3 to
Ø0.5, Black polyamide



SHSS

Shoulder screw
stainless steel 416,
Pre-treated 416



ZG1

Plastic spur gear,
Machined plastic
(delrin)



NSO

Housing for open
linear bearing,
Opened - long

Complementary products



KK

Rounded end feather
key, Steel