

# Chain sprocket with **hardened teeth**

## DIN12B-1 3/4"

C45 tempered steel



2 threaded holes

- Pitch 19,05mm (DIN 12B-1)
- Roller diameter 12,07mm
- Materials:  
C45 steel UNI7845  
Hardened teeth 45-53HRC



### Accessory

- SBR-750/M chain

### Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

Bore and keyway

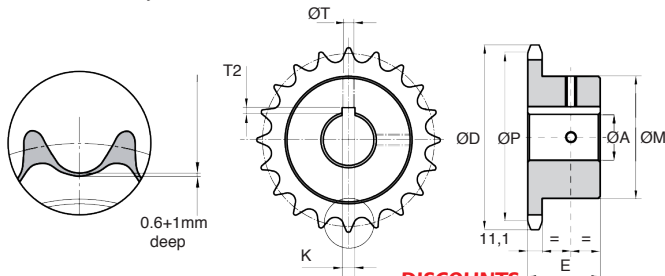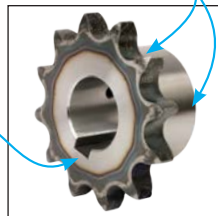

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each
										1 to 5
PCS75-12H-20K	12	73,60	81,80	52	35	20	6	2,80	M5	14,47 €
PCS75-12H-22K										14,47 €
PCS75-12H-24K										14,47 €
PCS75-12H-25K										14,47 €
PCS75-12H-28K										14,47 €
PCS75-12H-30K										14,47 €
PCS75-13H-20K	13	79,60	87,10	58	35	20	6	2,80	M5	16,06 €
PCS75-13H-22K										16,06 €
PCS75-13H-24K										16,06 €
PCS75-13H-25K										16,06 €
PCS75-13H-28K										16,06 €
PCS75-13H-30K										16,06 €
PCS75-13H-32K										16,06 €
PCS75-13H-35K										16,06 €

All dimensions in mm

## DISCOUNTS

<b>Qty</b>	1+	6+	20+	40+
<b>Disc.</b>	List	-12%	-25%	On request

Part N°	Z					K				Price each 1 to 5					
	Teeth	ØP	ØD	ØM	E	ØA	(H9)	T2	ØT						
PCS75-14H-20K	14	85,61	93,80	64	35	20	6	2,80	M5	17,61 €					
PCS75-14H-22K						22	6	2,80	M5	17,61 €					
PCS75-14H-24K						24	8	3,30	M6	17,61 €					
PCS75-14H-25K						25	8	3,30	M6	17,61 €					
PCS75-14H-28K						28	8	3,30	M6	17,61 €					
PCS75-14H-30K						30	8	3,30	M6	17,61 €					
PCS75-14H-32K						32	10	3,30	M8	17,61 €					
PCS75-14H-35K						35	10	3,30	M8	17,61 €					
PCS75-15H-20K						15	91,63	99,20	70	35	20	6	2,80	M5	20,07 €
PCS75-15H-22K											22	6	2,80	M5	20,07 €
PCS75-15H-24K	24	8	3,30	M6	20,07 €										
PCS75-15H-25K	25	8	3,30	M6	20,07 €										
PCS75-15H-28K	28	8	3,30	M6	20,07 €										
PCS75-15H-30K	30	8	3,30	M6	20,07 €										
PCS75-15H-32K	32	10	3,30	M8	20,07 €										
PCS75-15H-35K	35	10	3,30	M8	20,07 €										
PCS75-15H-38K	38	10	3,30	M8	20,07 €										
PCS75-15H-40K	40	12	3,30	M10	20,07 €										
PCS75-16H-20K	16	97,65	105,50	75	35	20	6	2,80	M5	22,60 €					
PCS75-16H-22K						22	6	2,80	M5	22,60 €					
PCS75-16H-24K						24	8	3,30	M6	22,60 €					
PCS75-16H-25K						25	8	3,30	M6	22,60 €					
PCS75-16H-28K						28	8	3,30	M6	22,60 €					
PCS75-16H-30K						30	8	3,30	M6	22,60 €					
PCS75-16H-32K						32	10	3,30	M8	22,60 €					
PCS75-16H-35K						35	10	3,30	M8	22,60 €					
PCS75-16H-38K						38	10	3,30	M8	22,60 €					
PCS75-16H-40K						40	12	3,30	M10	22,60 €					
PCS75-17H-22K	17	103,67	111,20	80	35	22	6	2,80	M5	24,97 €					
PCS75-17H-24K						24	8	3,30	M6	24,97 €					
PCS75-17H-25K						25	8	3,30	M6	24,97 €					
PCS75-17H-28K						28	8	3,30	M6	24,97 €					
PCS75-17H-30K						30	8	3,30	M6	24,97 €					
PCS75-17H-32K						32	10	3,30	M8	24,97 €					
PCS75-17H-35K						35	10	3,30	M8	24,97 €					
PCS75-17H-38K						38	10	3,30	M8	24,97 €					
PCS75-17H-40K						40	12	3,30	M10	24,97 €					
PCS75-18H-22K						18	109,71	118,00	80	35	22	6	2,80	M5	26,89 €
PCS75-18H-24K	24	8	3,30	M6	26,89 €										
PCS75-18H-25K	25	8	3,30	M6	26,89 €										
PCS75-18H-28K	28	8	3,30	M6	26,89 €										
PCS75-18H-30K	30	8	3,30	M6	26,89 €										
PCS75-18H-32K	32	10	3,30	M8	26,89 €										
PCS75-18H-35K	35	10	3,30	M8	26,89 €										
PCS75-18H-38K	38	10	3,30	M8	26,89 €										
PCS75-18H-40K	40	12	3,30	M10	26,89 €										

# Chain sprocket with **hardened teeth**

## DIN12B-1 3/4"

### C45 tempered steel



2 threaded holes

- Pitch 19,05mm (DIN 12B-1)
- Roller diameter 12,07mm
- Materials:  
C45 steel UNI7845  
Hardened teeth 45-53HRC





### Accessory

- SBR-750/M chain

### Info

- DIN 6885 keyway on the central tooth line
- Threaded hole on key and at 90°

Bore and keyway

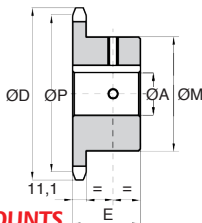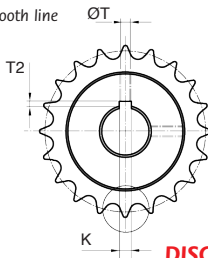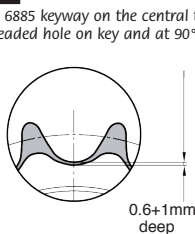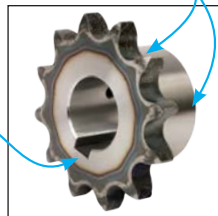

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z Teeth	ØP	ØD	ØM	E	ØA	K (H9)	T2	ØT	Price each 1 to 5
PCS75-19H-25K	19	115,75	123,30	80	35	25	8	3,30	M6	29,31 €
PCS75-19H-28K						28	8	3,30	M6	29,31 €
PCS75-19H-30K						30	8	3,30	M6	29,31 €
PCS75-19H-32K						32	10	3,30	M8	29,31 €
PCS75-19H-35K						35	10	3,30	M8	29,31 €
PCS75-19H-38K						38	10	3,30	M8	29,31 €
PCS75-19H-40K						40	12	3,30	M10	29,31 €
PCS75-19H-42K						42	12	3,30	M10	29,31 €
PCS75-19H-45K						45	14	3,80	M12	29,31 €
PCS75-20H-25K						20	121,78	129,70	80	35
PCS75-20H-28K	28	8	3,30	M6	30,94 €					
PCS75-20H-30K	30	8	3,30	M6	30,94 €					
PCS75-20H-32K	32	10	3,30	M8	30,94 €					
PCS75-20H-35K	35	10	3,30	M8	30,94 €					
PCS75-20H-38K	38	10	3,30	M8	30,94 €					
PCS75-20H-40K	40	12	3,30	M10	30,94 €					
PCS75-20H-42K	42	12	3,30	M10	30,94 €					
PCS75-20H-45K	45	14	3,80	M12	30,94 €					

All dimensions in mm

## DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part N°	Z					K				Price each 1 t5
	Teeth	ØP	ØD	ØM	E	ØA	(H9)	T2	ØT	
PCS75-21H-28K	21	127,82	135,40	90	40	28	8	3,30	M6	36,62 €
PCS75-21H-30K						30	8	3,30	M6	36,62 €
PCS75-21H-32K						32	10	3,30	M8	36,62 €
PCS75-21H-35K						35	10	3,30	M8	36,62 €
PCS75-21H-38K						38	10	3,30	M8	36,62 €
PCS75-21H-40K						40	12	3,30	M10	36,62 €
PCS75-21H-42K						42	12	3,30	M10	36,62 €
PCS75-21H-45K						45	14	3,80	M12	36,62 €
PCS75-21H-48K						48	14	3,80	M12	36,62 €
PCS75-21H-50K						50	14	3,80	M12	36,62 €
PCS75-23H-28K	23	139,90	147,40	90	40	28	8	3,30	M6	41,04 €
PCS75-23H-30K						30	8	3,30	M6	41,04 €
PCS75-23H-32K						32	10	3,30	M8	41,04 €
PCS75-23H-35K						35	10	3,30	M8	41,04 €
PCS75-23H-38K						38	10	3,30	M8	41,04 €
PCS75-23H-40K						40	12	3,30	M10	41,04 €
PCS75-23H-42K						42	12	3,30	M10	41,04 €
PCS75-23H-45K						45	14	3,80	M12	41,04 €
PCS75-23H-48K						48	14	3,80	M12	41,04 €
PCS75-23H-50K						50	14	3,80	M12	41,04 €
PCS75-24H-28K	24	145,94	154,10	90	40	28	8	3,30	M6	42,39 €
PCS75-24H-30K						30	8	3,30	M6	42,39 €
PCS75-24H-32K						32	10	3,30	M8	42,39 €
PCS75-24H-35K						35	10	3,30	M8	42,39 €
PCS75-24H-38K						38	10	3,30	M8	42,39 €
PCS75-24H-40K						40	12	3,30	M10	42,39 €
PCS75-24H-42K						42	12	3,30	M10	42,39 €
PCS75-24H-45K						45	14	3,80	M12	42,39 €
PCS75-24H-48K						48	14	3,80	M12	42,39 €
PCS75-24H-50K						50	14	3,80	M12	42,39 €
PCS75-25H-28K	25	152,00	159,50	90	40	28	8	3,30	M6	44,96 €
PCS75-25H-30K						30	8	3,30	M6	44,96 €
PCS75-25H-32K						32	10	3,30	M8	44,96 €
PCS75-25H-35K						35	10	3,30	M8	44,96 €
PCS75-25H-38K						38	10	3,30	M8	44,96 €
PCS75-25H-40K						40	12	3,30	M10	44,96 €
PCS75-25H-42K						42	12	3,30	M10	44,96 €
PCS75-25H-45K						45	14	3,80	M12	44,96 €
PCS75-25H-48K						48	14	3,80	M12	44,96 €
PCS75-25H-50K						50	14	3,80	M12	44,96 €

Fax

0 825 88 6000  
Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

311

## Our other products



CHAupa  
Front hinge, 270°



RMSA  
Adjustable shock-absorber, Adjustable



PR820  
Idler sprocket for slat top chain, Rangs 820 and 815



RAGFLOWsupport  
Floway2® Roller track accessory, Roller track support



PDD  
Actuating plunger, Non-rotating detector shaft



HLA28  
Right angle spiroid gearbox, Up to 182Nm



PSG125S  
Spur gear - precision range, Stainless steel 316



BSM  
Spring plunger with internal hexagonal socket, steel body and pin



PITA  
Locking bolt, with T handle



SH1  
Parallel axis helical gear, Steel 20NCD2



PSG15  
Spur gear - precision range, Pre-hardened Steel 35NCD6



RFV50  
Stainless steel worm and wheel gearbox, up to 80 Nm

## Complementary products



KK  
Rounded end feather key, Steel