

Pitch
8mm C45 steel



- Pitch 8mm (DIN 05B-1)
- Roller diameter 5mm
- Material:

C45 UNI7845 steel


- HPC are unable to modify these parts

-**The prebore dimensions are given as a guide only and are subject to change

Accessories

- Chain part number SBR-8/M, SBS-8/M

Economy range

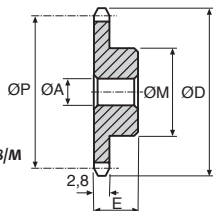


DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z teeth	ØP	ØD	ØM	ØA**	E	Weight (kg)	Price each
PCS8-8	8	20,90	24,0	13	6	12	0,01	1,25 €
PCS8-9	9	23,39	26,6	15	6	12	0,02	1,29 €
PCS8-10	10	25,89	29,2	17	8	12	0,02	1,37 €
PCS8-11	11	28,39	31,7	18	8	13	0,03	1,47 €
PCS8-12	12	30,91	34,2	20	8	13	0,04	2,14 €
PCS8-13	13	33,42	36,7	23	8	13	0,05	2,22 €
PCS8-14	14	35,95	39,2	25	8	13	0,05	2,48 €
PCS8-15	15	38,48	41,7	28	8	13	0,07	2,76 €
PCS8-16	16	41,01	44,3	30	8	14	0,08	3,02 €
PCS8-17	17	43,53	46,8	30	8	14	0,09	3,02 €
PCS8-18	18	46,07	49,3	30	8	14	0,09	3,36 €
PCS8-19	19	48,61	51,9	30	8	14	0,09	3,57 €
PCS8-20	20	51,14	54,4	30	8	14	0,10	3,69 €
PCS8-21	21	53,68	57,0	35	8	14	0,12	4,33 €
PCS8-23	23	58,75	62,0	35	8	14	0,13	4,58 €
PCS8-25	25	63,83	67,5	35	8	14	0,15	5,08 €
PCS8-27	27	68,91	72,2	40	10	16	0,20	5,34 €
PCS8-30	30	76,53	79,8	40	10	16	0,22	6,35 €
PCS8-33	33	84,16	87,5	40	10	16	0,24	7,23 €
PCS8-35	35	89,25	92,5	40	10	16	0,25	8,20 €
PCS8-36	36	91,79	95,0	40	10	16	0,26	8,96 €
PCS8-38	38	96,88	100,2	40	10	16	0,28	9,00 €
PCS8-39	39	99,42	102,7	40	10	16	0,29	9,13 €
PCS8-40	40	101,97	105,3	40	10	16	0,58	10,52 €
PCS8-45	45	114,69	118,0	60	12	20	0,67	14,73 €
PCS8-48	48	122,32	125,6	60	12	20	0,63	16,37 €
PCS8-50	50	127,41	130,7	60	12	20	1,00	17,04 €

Dimensions in mm

 
Our other products



PRF PSP_PR
Dual purpose strip
and cover for
aluminium profile,
Inserts into slot



 HLC24
Right angle spiro
bevel gearbox, Up to
78Nm



AC
Strike for toggle latch,
15mm



gt64r
Rotating bent lever
with spring, Increased
fitting tolerances



SEH
Horizontal stirrup
toggle clamp,
Horizontal Latch
clamp - stainless ...



IN1
Internal gear, Steel
20NCD2



PX
Optional output shaft
stainless steel, P
gearboxes double
sided outp...



GP75
Spring loaded toggle
latch, Standard
(GP75)



WW16
Drylin® W slide, slide
assembly



BUT
Panel stop, Panel stop



CHTRB
Single and dual
output gearboxes, Up
to 53,1 Nm



SLV
Vertical toggle clamp,
Vertical Lever Clamp -
stainless steel

Complementary products



SUA4
Single chain supplied
by the metre, Steel



SUA4_L
Chain link, Steel