

Recessed handle, clip-in

PENC

Thermoplastic

- Handle for carrying or push/pull operations, mounting by clipping into a panel

Material:



Black thermoplastic (ABS)

Info.

- Gripping force is 750N per pair in steel and sheet metal housings

Applications

- Ideal for use on metal enclosures or drawers

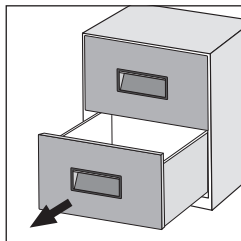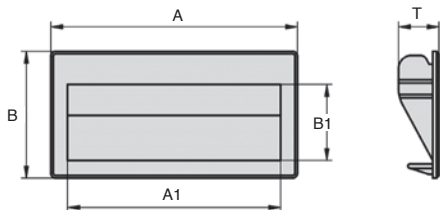

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	B	B1	T	Mounting hole	For wall thickness (mm)	Load (N)	Stock*	Price each 1 to 5
PENC40-90	90	79	40,0	30,0	16	83X34	0,75 à 1,5	375	✓	5,02 €
PENC56-110	110	95	56,3	33,8	18	103X49	0,75 à 1,5	375	-	5,67 €
PENC79-187	187	164	79,0	54,0	22	171X73	1,5 à 2	375	✓	7,38 €

Dimensions in mm

Our other products



CHINV
Invisible hinge,
Invisible - Opening up to 90°



MHSC
Single-disc flexible
coupling, Single disk




GET-AL
Jaw coupling,
economy range,
Aluminium



M
Bellows cover,
Accessory:



 GAL_25
Ø25 conveyor roller,
Without ball bearing



PM4
Worm and wheel set,
Machined plastic
(delrin)



CHM110
Worm and wheel gear
reducer, up to 980
Nm




GE14
Toggle latches, With
padlock-holder



MSP3815
Masterplate®
glueable insert
rectangular,
rectangular with



 DBL820
Idler for slat top
chain, Ranges 820
and 815



EZY
Cylindrical stop, Steel



METC
Flanged sintered
bronze bush, Self-
lubricating sintered
bronze

Complementary products



PENV
Recessed handle,
screw fixing



PO
Pull handle - Multi-
sector, Smooth hole