

# Recessed handle, clip-in

## PENC

## Thermoplastic

- Handle for carrying or push/pull operations, mounting by clipping into a panel

Material:



Black thermoplastic (ABS)

### Info.

- Gripping force is 750N per pair in steel and sheet metal housings

### Applications

- Ideal for use on metal enclosures or drawers

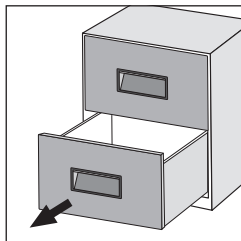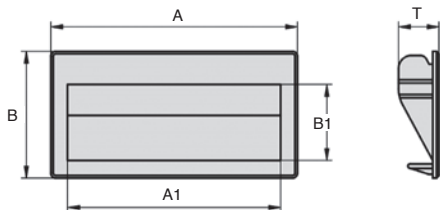

Typical application


### DISCOUNTS

 Qty	1+	6+	20+	50+	100+	250+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	A	A1	B	B1	T	Mounting hole	For wall thickness (mm)	Load (N)	Stock*	Price each 1 to 5
PENC40-90	90	79	40,0	30,0	16	83X34	0,75 à 1,5	375	✓	5,02 €
PENC56-110	110	95	56,3	33,8	18	103X49	0,75 à 1,5	375	-	5,67 €
PENC79-187	187	164	79,0	54,0	22	171X73	1,5 à 2	375	✓	7,38 €

Dimensions in mm

## Our other products



M1

Worm and wheel set,  
Bronze



HCV

V-rail guidance  
Simple Select®  
system, on rail




CLG2

Moulded plastic spur  
gear, Moulded plastic  
(nylon)



EPE

 Wing nuts Hygienic  
Design®, Narrow




TBV

Manual lifting tables,  
3kg



TUBE25\_25

 Square Tube,  
Aluminium or  
Stainless steel



RLR

Roll-Ring® chain  
tensioner, Roll-Ring®  
Self-adjusting



SHA\_PTR

Handwheel with  
folding handle,  
Polyamide



HTD5M-BAR

HTD type tooth bar  
stock, HTD5



TCSH

Automatic chain  
tensioner, With  
support



CMAss

Eye bolt stainless  
steel, Stainless steel



ZG0

Plastic spur gear,  
Machined plastic  
(delrin)

## Complementary products



PENV

Recessed handle,  
screw fixing



PO

Pull handle - Multi-  
sector, Smooth hole