

# Recessed handle, clip-in

PENC

Thermoplastic

- Handle for carrying or push/pull operations, mounting by clipping into a panel

Material:



Black thermoplastic (ABS)

## Info.

- Gripping force is 750N per pair in steel and sheet metal housings

## Applications

- Ideal for use on metal enclosures or drawers

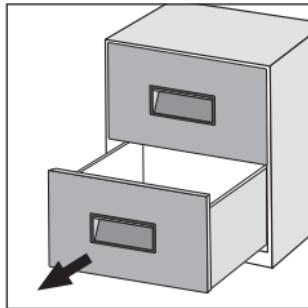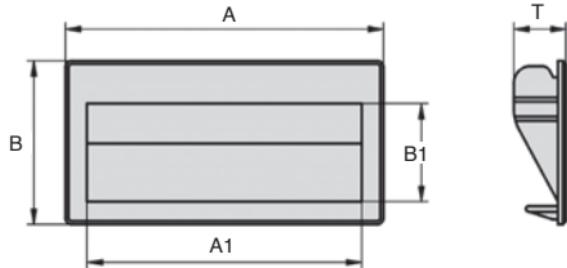

Typical application

## DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	B	B1	T	Mounting hole	For wall thickness (mm)	Load (N)	Stock*	Price each 1 to 5
PENC40-90	90	79	40,0	30,0	16	83X34	0,75 à 1,5	375	✓	5,02 €
PENC56-110	110	95	56,3	33,8	18	103X49	0,75 à 1,5	375	-	5,67 €
PENC79-187	187	164	79,0	54,0	22	171X73	1,5 à 2	375	✓	7,38 €

Dimensions in mm

## Our other products



MCLred

Reducing sleeve  
female/female,  
Cylindrical - steel



HLA24

Right angle spiro  
bevel gearbox, Up to  
78Nm



GDR880

Straight track for slat  
top chain, Ranges 880  
and 881



HW\_HT

Half-rail guide, Wheel



H0

Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



AHEX

Hexagonal shaft,  
Hexagonal shaft




GMK17\_RG

Joint for guiding  
profile, Rounded



FF50

Offset spur gear  
reducer, from 111 to  
425 Nm

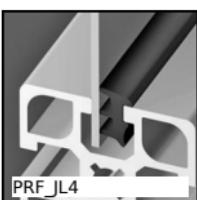

PRF\_JL4

Lip seal for panel,  
Door seal - Ø 4mm



DOMI80

Accessories, Clamping  
lever



PO

Pull handle - Multi-  
sector, Tapped  
recessed insert



BPM\_LOK

Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -  
Stainless ...

## Complementary products



PENV

Recessed handle,  
screw fixing



PO

Pull handle - Multi-  
sector, Smooth hole