

Recessed handle, clip-in

PENC

Thermoplastic

- Handle for carrying or push/pull operations, mounting by clipping into a panel

Material:



Black thermoplastic (ABS)

Info.

- Gripping force is 750N per pair in steel and sheet metal housings

Applications

- Ideal for use on metal enclosures or drawers

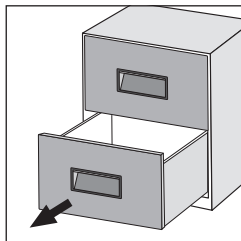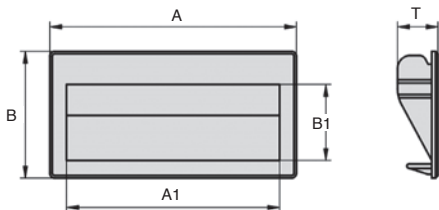

Typical application


DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	B	B1	T	Mounting hole	For wall thickness (mm)	Load (N)	Stock*	Price each 1 to 5
PENC40-90	90	79	40,0	30,0	16	83X34	0,75 à 1,5	375	✓	5,02 €
PENC56-110	110	95	56,3	33,8	18	103X49	0,75 à 1,5	375	-	5,67 €
PENC79-187	187	164	79,0	54,0	22	171X73	1,5 à 2	375	✓	7,38 €

Dimensions in mm

 Our other products



BETASS

Hitch pin, Hitch



COA-COG

Surface mounting plate, Surface mounting plate for ball joint



BEAB

Knob star grip antibacterial, Star, anti-bacterial



PRF_RR

Coupling bar for aluminium profile, Coupling bar



KKSS

Rounded end feather key, Stainless steel



DOMI50

Accessories, Fixing kit



GAC

Lock for latch clamp, Strike plate



P20

Worm and wheel gear reducer, up to 5 Nm




MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



CAP881

Side flexing slim slot top chain stainless

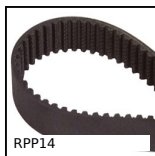

RPP14

RPP heavy duty timing belt, RPP14



PRF1945

Standard aluminium profile, 19 x 45 mm

Complementary products



PENV

Recessed handle, screw fixing



PO

Pull handle - Multi-sector, Smooth hole