

Recessed handle, clip-in

PENC

Thermoplastic

- Handle for carrying or push/pull operations, mounting by clipping into a panel

Material:



Black thermoplastic (ABS)

Info.

- Gripping force is 750N per pair in steel and sheet metal housings

Applications

- Ideal for use on metal enclosures or drawers

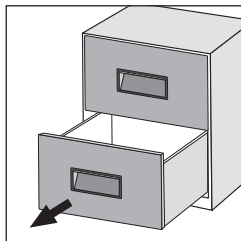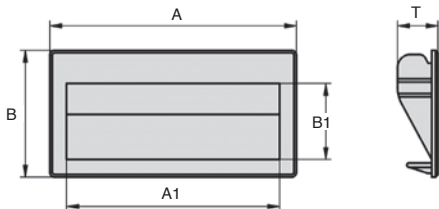

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc. List	-5%	-10%	-15%	-20%	On request	

Part number	A	A1	B	B1	T	Mounting hole	For wall thickness (mm)	Load (N)	Stock*	Price each 1 to 5
PENC40-90	90	79	40,0	30,0	16	83X34	0,75 à 1,5	375	✓	5,02 €
PENC56-110	110	95	56,3	33,8	18	103X49	0,75 à 1,5	375	-	5,67 €
PENC79-187	187	164	79,0	54,0	22	171X73	1,5 à 2	375	✓	7,38 €

Dimensions in mm

Our other products



UTKpwc

Utilitrak® 3 wheels carriage, Polymer series V wheels



PRES2HR

Manual workbench press, Force up to 200kg



RBG

Wheel, Grey rubber - Polypropylene rim




CHT56

Asynchronous AC motor 0.09kW, 0.09kW



RBGtc

 Swivel castor with central hole, Steel - grey rubber



B

Steel bevel gear, 1:1



PGM52-M4

Pull handle, Brass



BPM_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...



FDSQ

Flexible drive shaft, Masterflex® Steel, with PVC casing



GET-AL

Jaw coupling, economy range, Aluminium



CABPVC

PVC covered galvanised steel cable, Galvanised



PLA

Flat magnet, Flat magnet with threaded hole

Complementary products



PENV

Recessed handle, screw fixing



PO

Pull handle - Multi-sector, Smooth hole