

Recessed handle, screw fixing

Thermoplastic

PENV

Improved grip

- Handle for carrying or push/pull operations, mounts by clipping into a panel.

- Material:



Black thermoplastic (ABS)

Info.


- Maximum load: 500N per pair

Applications

- Ideal for use on metal enclosures or drawers

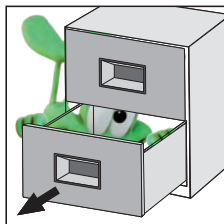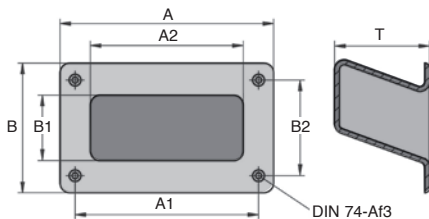

Typical application

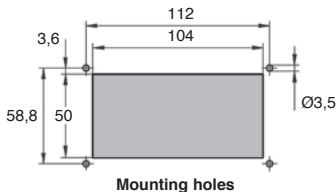

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	A2	B	B1	B2	T	Load (N)	Stock*	Price each 1 to 5
PENV79-131	131	112	94	79,0	40,0	58,8	58	250	✓	6,56 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



NPTF30

Spacer for tube carrier, Fixing accessory Ø14 to Ø20



PC550K

Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)



DCA

Suction cup, 1.5 bellows, silicon



TK

Topball self-aligning linear bearing, Topball self-aligning



 
RURt

Swivel castor with central hole, Polyurethane - Aluminium rim (Free



ATZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



T0

Torsion spring, Stainless steel



BCM_CC

Modular cylindrical brush, Horsehair bristles



UGPc

Actuator guide kit, Short bearing



G0

Steel spur gear, Steel 20NCD2



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



GCH

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...

Complementary products



PENC

Recessed handle, clip-in



PO

Pull handle - Multi-sector, Smooth hole