

Recessed handle, screw fixing

Thermoplastic

PENV

Improved grip

- Handle for carrying or push/pull operations, mounts by clipping into a panel.

- Material:



Black thermoplastic (ABS)

Info.


- Maximum load: 500N per pair

Applications

- Ideal for use on metal enclosures or drawers

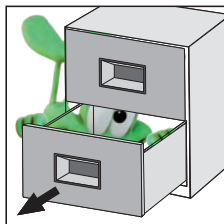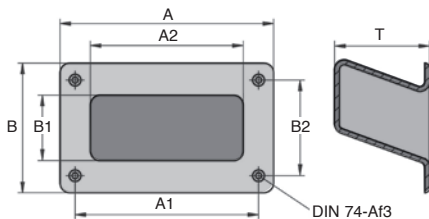

Typical application

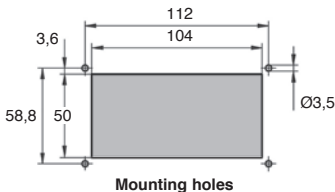

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	A1	A2	B	B1	B2	T	Load (N)	Stock*	Price each 1 to 5
PENV79-131	131	112	94	79,0	40,0	58,8	58	250	✓	6,56 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel


cial2@hpceurope.com

HPC

SUPPLEMENT 2019

155

Our other products

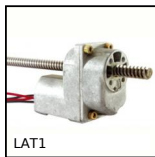

LAT1

1A motorised linear actuator, 1 ampere



EPRC

High helix leadscrew, Cylindrical nut - up to 40mm per rotation



VQTplq

Quarter-turn clamp lock - Clamping plate, Wall mounting



SSG1

Stainless steel spur gear, Stainless steel 304L



BOX-TOR-H

Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00



ADL_M

Male eye bolt conforms to DIN580, Stainless steel



DB

Steel bevel gear, 2:1



RFK48C

Hypoid gearbox - Stainless steel, up to 350 Nm



CDP

Flanged drill bushing, Steel



G0

Steel spur gear, Steel 20NCD2



GBS

Nut for ballscrew, Flanged ballscrew nut



SC2

2 part rigid shaft clamp, Clamping jaw

Complementary products



PENC

Recessed handle, clip-in



PO

Pull handle - Multi-sector, Smooth hole