


- Levelling support for small parts
- Materials:
  - Rod: steel or stainless steel 304
  - Base: NBR rubber hardness Shore 70

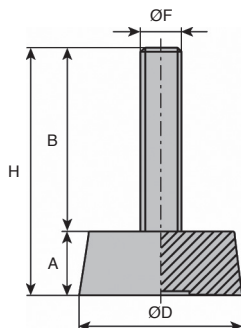

### DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	ØD	ØF	A	H	B	Max. load (N)	Stock*	Price each 1 to 49
<b>Steel</b>								
PFC40-8	40	M8	16	41	25	1800	✓	3,48 €
PFC40-10	40	M10	16	41	25	2250	✓	4,09 €
PFC40-12	40	M12	16	41	25	3150	✓	4,75 €
<b>Stainless steel</b>								
PFC40-8/SS	40	M8	16	41	25	1800	✓	4,09 €
PFC40-10/SS	40	M10	16	41	25	2250	✓	4,44 €
PFC40-12/SS	40	M12	16	41	25	3150	✓	6,04 €

\*Depending on availability - Dimensions in mm

## Our other products



PRESSHR  
Manual workbench  
press, Force up to  
500kg



HSSss  
Stainless steel  
shoulder screw  
ISO7379, Stainless  
steel ISO 7379



COA-COG  
Surface mounting  
plate, Surface  
mounting plate for  
clevis



M0  
Worm and wheel set,  
Bronze



PFM  
Fixed levelling foot,  
Flanged plate



KB\_OP  
Open precision linear  
bearing, Precision -  
steel



ALIDRP240  
24V DC power supply,  
10 A



BPPss  
Pressed stainless  
steel pillow block,  
Stainless steel



HLUMss  
Revolving handle for  
handwheel, Stainless  
steel 316



TB8  
Cylindrical roller  
thrust bearing, Steel



CHA35  
Hinge for aluminium  
profile, Hinge



CHA225  
Screwed hinge with  
threaded insert, 225  
degrees

## Complementary products