

Fixed rubber foot



PFC


Maximum load 3,150N

- Levelling support for small parts

- Materials:

Rod: steel or stainless steel 304

Base: NBR rubber hardness Shore 70

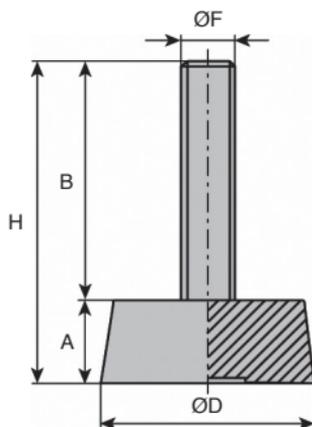

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	ØD	ØF	A	H	B	Max. load (N)	Stock*	Price each 1 to 49
Steel								
PFC40-8	40	M8	16	41	25	1800	✓	3,76 €
PFC40-10	40	M10	16	41	25	2250	✓	4,42 €
PFC40-12	40	M12	16	41	25	3150	✓	5,13 €
Stainless steel								
PFC40-8/SS	40	M8	16	41	25	1800	✓	4,42 €
PFC40-10/SS	40	M10	16	41	25	2250	✓	4,80 €
PFC40-12/SS	40	M12	16	41	25	3150	✓	7,78 €

*Depending on availability - Dimensions in mm