


- Levelling support for small parts
- Materials:
 - Rod: steel or stainless steel 304
 - Base: NBR rubber hardness Shore 70

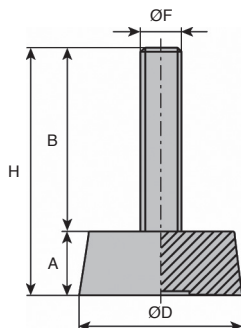

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	ØD	ØF	A	H	B	Max. load (N)	Stock*	Price each 1 to 49
Steel								
PFC40-8	40	M8	16	41	25	1800	✓	3,48 €
PFC40-10	40	M10	16	41	25	2250	✓	4,09 €
PFC40-12	40	M12	16	41	25	3150	✓	4,75 €
Stainless steel								
PFC40-8/SS	40	M8	16	41	25	1800	✓	4,09 €
PFC40-10/SS	40	M10	16	41	25	2250	✓	4,44 €
PFC40-12/SS	40	M12	16	41	25	3150	✓	6,04 €

 
*Depending on availability - Dimensions in mm

Our other products



PRFSRAD

Dual lock for aluminium profile, Quick fitting, self locking door du...



CFC

Spring loaded position switch, Electric contact



GPBSS

Threaded spherical knob, Aluminium



PSG125S

Spur gear - precision range, Stainless steel 316



PSG15

Spur gear - precision range, Stainless steel 316



 
CLSCLP_SS

Clevis components, short version, Stainless steel - short range



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



VHTM

Hexagonal headed screw Hygienic Design®, Stainless steel



BPL

Ball transfer unit light duty, Light



HLC24

Right angle spiro bevel gearbox, Up to



SH0

Parallel axis helical gear, Steel 20NCD2

Complementary products