

# Carrying handle

PGM

Aluminium or brass

- Gripping handle for both pushing and pulling

- Rear mounting



- Materials:

Aluminium, natural finish

Aluminium, polished

Chromed brass

Nickel plated brass

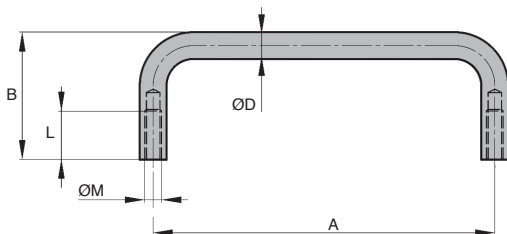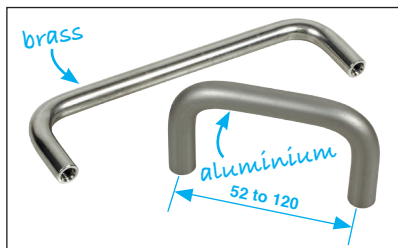

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-15%	On request	

Part number	Material	Finish	A	B	ØD	L	ØM	Weight (g)	Stock*	Price each 1 to 5
PGM52-M4/ALA	aluminium anodized, natural	natural	52	34	8	10	M4	14	✓	7,19 €
PGM80-M4/ALA	aluminium anodized, natural	natural	80	34	8	12	M4	17	-	8,02 €
PGM100-M4/ALP	aluminium	polished	100	30	7	8	M4	14	✓	4,33 €
PGM100-M4/ALA	aluminium anodized, natural	natural	100	34	8	12	M4	20	✓	8,47 €
PGM100-M4/BRC	brass	chromed	100	30	7	8	M4	44	✓	6,65 €
PGM100-M4/BRN	brass	nickel plated	100	30	7	8	M4	44	-	6,56 €
PGM120-M4/ALA	aluminium anodized, natural	natural	120	34	8	10	M4	23	✓	9,01 €

Dimensions in mm

HPC

WEB  
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



RDERSS  
Stainless steel manual rigging screw, Stainless steel - manual



GARQT  
Quarter turn lock pin for clamping, Quarter turn



EHD06  
Internal epicyclic servo reducers, from 8 to 19 Nm



CHMR40  
Worm and wheel gear reducer, up to 57 Nm



AT5-BAR  
AT type tooth bar stock, AT5




CHAC4040NP  
Square hinge with riveted pin, not drilled, Square with riveted pin,...



SLH  
Horizontal toggle clamp, Horizontal Lever Clamp - steel



 SVR30  
Screwjack with travelling nut, with moving nut



M1  
Worm and wheel set, Machined plastic (delrin)



BLHB30  
Right angled gearbox, bored shafts, up to 4.47 Nm



GB-RA  
Brass spur gear, Brass CuZn39Pb3



CHNrb  
Warning chain with red and white links, Steel

## Complementary products



PGM52-M4  
Pull handle, Brass



PGMSS  
Stainless steel pull handle, Stainless steel



PO  
Pull handle - Multi-sector, Tapped recessed insert



PGMT  
Pull handle, Stainless steel