

Carrying handle

PGM

Aluminium or brass

- Gripping handle for both pushing and pulling

- Rear mounting



- Materials:

Aluminium, natural finish

Aluminium, polished

Chromed brass

Nickel plated brass

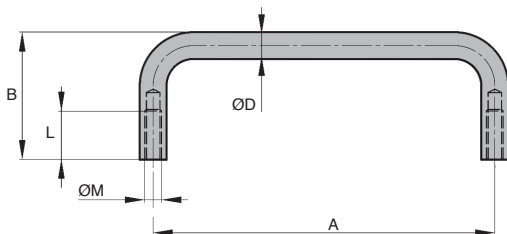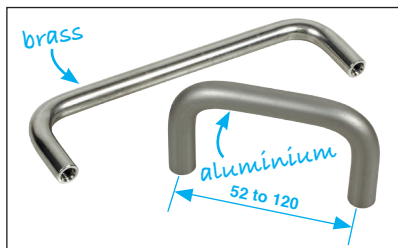

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-15%	On request	

Part number	Material	Finish	A	B	ØD	L	ØM	Weight (g)	Stock*	Price each 1 to 5
PGM52-M4/ALA	aluminium anodized, natural	natural	52	34	8	10	M4	14	✓	7,19 €
PGM80-M4/ALA	aluminium anodized, natural	natural	80	34	8	12	M4	17	-	8,02 €
PGM100-M4/ALP	aluminium	polished	100	30	7	8	M4	14	✓	4,33 €
PGM100-M4/ALA	aluminium anodized, natural	natural	100	34	8	12	M4	20	✓	8,47 €
PGM100-M4/BRC	brass	chromed	100	30	7	8	M4	44	✓	6,65 €
PGM100-M4/BRN	brass	nickel plated	100	30	7	8	M4	44	-	6,56 €
PGM120-M4/ALA	aluminium anodized, natural	natural	120	34	8	10	M4	23	✓	9,01 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CNA-CNG
Right angled mounting plate, Right angled mounting plate for clevis



BPPE
Ball transfer unit push fit, Light



DCG
Suction cup, 2.5 bellows, silicon



LFM
Steel leadscrew, Medium carbon steel - 1 thread



J64
Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - In-line



GCT
Pipe linch pin, Tube linch pin



VTHbr
Hexagonal headed screw VTH - DIN933, Brass



GPLbr
Brush, brass



LRX
Linear roller slide, Rail - from 9410 to



Gdal
Double universal joint eco series, Low duty



AKN
Bellows coupling Gerwah®, from 22 to



MEP
Revolving handle for handwheel, Fixed

Complementary products



PGM52-M4
Pull handle, Brass



PGMSS
Stainless steel pull handle, Stainless steel



PO
Pull handle - Multi-sector, Tapped recessed insert



PGMT
Pull handle, Stainless steel