

# Carrying handle

PGM

Aluminium or brass

- Gripping handle for both pushing and pulling

- Rear mounting



- Materials:

Aluminium, natural finish

Aluminium, polished

Chromed brass

Nickel plated brass

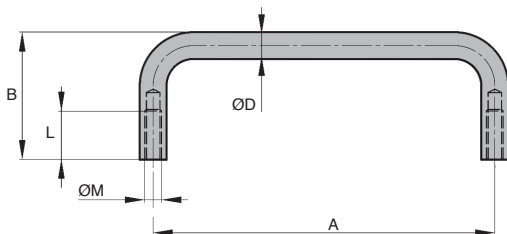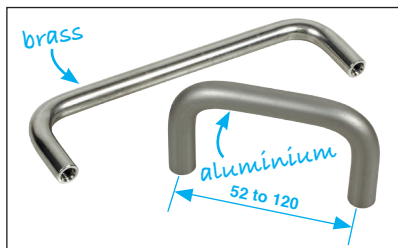

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-15%	On request	

Part number	Material	Finish	A	B	ØD	L	ØM	Weight (g)	Stock*	Price each 1 to 5
PGM52-M4/ALA	aluminium anodized, natural	natural	52	34	8	10	M4	14	✓	7,19 €
PGM80-M4/ALA	aluminium anodized, natural	natural	80	34	8	12	M4	17	-	8,02 €
PGM100-M4/ALP	aluminium	polished	100	30	7	8	M4	14	✓	4,33 €
PGM100-M4/ALA	aluminium anodized, natural	natural	100	34	8	12	M4	20	✓	8,47 €
PGM100-M4/BRC	brass	chromed	100	30	7	8	M4	44	✓	6,65 €
PGM100-M4/BRN	brass	nickel plated	100	30	7	8	M4	44	-	6,56 €
PGM120-M4/ALA	aluminium anodized, natural	natural	120	34	8	10	M4	23	✓	9,01 €

Dimensions in mm

HPC

WEB  
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



AHEX  
Hexagonal shaft,  
Hexagonal shaft



P45  
Worm and wheel gear  
reducer, up to 40 Nm



BSM\_LOK  
Long-Lok spring  
plunger with internal  
hexagonal socket,  
LONG-LOK - s...



DOMI30  
Accessories, Fixing kit



RTN  
BoWex® curved tooth  
gear coupling, Nylon



RURt  
Swivel castor with  
central hole,  
Polyurethane -  
Aluminium rim (Free



AT5M AT10M  
AT type timing belt  
per metre, AT5 Steel  
cored polyurethane



PRF19\_E  
Bracket for aluminium  
profile, PRF19 to  
PRF45



ACL  
Joints for aluminium  
profile, Variable angle  
hinge



NSU  
Universal 90° support  
clamp, Universal 90°  
support clamp



METC  
Flanged sintered  
bronze bush, Self-  
lubricating sintered  
bronze



COA-COG  
Surface mounting  
plate, Surface  
mounting plate for  
ball joint

## Complementary products



PGM52-M4  
Pull handle, Brass



PGM55  
Stainless steel pull  
handle, Stainless steel



PO  
Pull handle - Multi-  
sector, Tapped  
recessed insert



PGM86-M5  
Pull handle,  
Thermoplastic