

Carrying handle

PGM

Aluminium or brass

- Gripping handle for both pushing and pulling

- Rear mounting



- Materials:

Aluminium, natural finish

Aluminium, polished

Chromed brass

Nickel plated brass

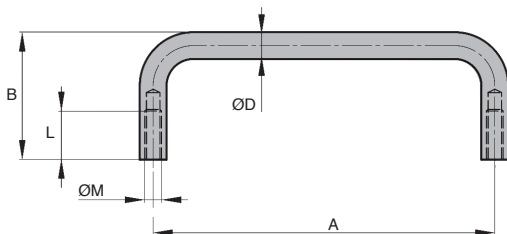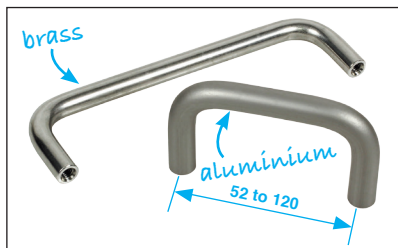

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-15%	On request	

Part number	Material	Finish	A	B	ØD	L	ØM	Weight (g)	Stock*	Price each 1 to 5
PGM52-M4/ALA	aluminium anodized, natural	natural	52	34	8	10	M4	14	✓	7,19 €
PGM80-M4/ALA	aluminium anodized, natural	natural	80	34	8	12	M4	17	-	8,02 €
PGM100-M4/ALP	aluminium	polished	100	30	7	8	M4	14	✓	4,33 €
PGM100-M4/ALA	aluminium anodized, natural	natural	100	34	8	12	M4	20	✓	8,47 €
PGM100-M4/BRC	brass	chromed	100	30	7	8	M4	44	✓	6,65 €
PGM100-M4/BRN	brass	nickel plated	100	30	7	8	M4	44	-	6,56 €
PGM120-M4/ALA	aluminium anodized, natural	natural	120	34	8	10	M4	23	✓	9,01 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



SCA_SS
Cable clamp, Stainless steel



CHT90
3 phase AC asynchronous motor, 1.1 to 1.85kW



RHTplss
High Temperature Castor, up to 200kg



BCM_CC
Modular cylindrical brush, Horsehair bristles



Q6
Ball bearing, Steel



PRFRTR
Connecting/joining, Cross connector



HDSS
Universal joint - stainless steel, Needle bearings - double



BIMSS
Index bolt, miniature - Stainless steel



ZG2
Spur gear, Machined plastic (delrin)



PLM-C
Magnetic stud, Cylindrical holding magnet



PPS25
Pinion shaft - precision range, Stainless steel



OP3_14_06
Numerical counter accessories, Reduction socket

Complementary products



PGM52-M4
Carrying handle, Brass



PGMSS
Carrying handle, Stainless steel



PO
Housing handle - Multi-sector, Tapped recessed insert



PGM86-M5
Carrying handle, Thermoplastic