

Carrying handle

PGM

Aluminium or brass

- Gripping handle for both pushing and pulling

- Rear mounting



- Materials:

Aluminium, natural finish

Aluminium, polished

Chromed brass

Nickel plated brass

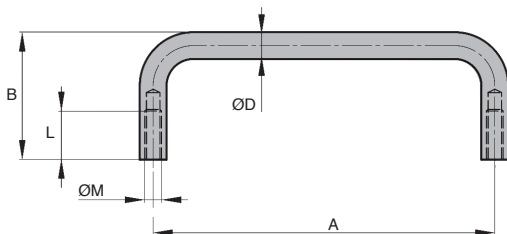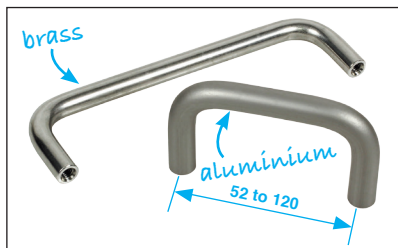

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-	-5%	-15%	On request

Part number	Material	Finish	A	B	ØD	L	ØM	Weight (g)	Stock*	Price each 1 to 5
PGM52-M4/ALA	aluminium anodized, natural	natural	52	34	8	10	M4	14	✓	7,19 €
PGM80-M4/ALA	aluminium anodized, natural	natural	80	34	8	12	M4	17	-	8,02 €
PGM100-M4/ALP	aluminium	polished	100	30	7	8	M4	14	✓	4,33 €
PGM100-M4/ALA	aluminium anodized, natural	natural	100	34	8	12	M4	20	✓	8,47 €
PGM100-M4/BRC	brass	chromed	100	30	7	8	M4	44	✓	6,65 €
PGM100-M4/BRN	brass	nickel plated	100	30	7	8	M4	44	-	6,56 €
PGM120-M4/ALA	aluminium anodized, natural	natural	120	34	8	10	M4	23	✓	9,01 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



GDR880

Straight track for slat top chain, Ranges 880 and 881



 
H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2



SA_SAKH

Housing for linear bearing, Closed - light load



PRF_TOOL

Assembly key for aluminium profile, Assembly key



BAGSS

Stainless steel Clamping collar, Stainless steel



PNA_R

PERIFLEX elastic coupling, Replacement tyre



PRF_ROUL

Castor for aluminium profile, No brake



DTR

Chain idler sprocket, Chain idler sprocket - Steel




T39_T49

Extension spring in metre length stainless steel, by the metre



SSE

Stainless steel spherical bearing, Stainless steel / PTFE

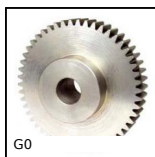

G0

Steel spur gear, Steel 20NCD2



PCS50SS

Chain sprocket - Stainless steel, 12.7mm (DIN 08B-1)

Complementary products



PGM52-M4

Pull handle, Aluminium



PGM52-M4

Pull handle, Brass



PGM86-M5

Pull handle, Thermoplastic



PGMSS

Stainless steel pull handle, Stainless steel