
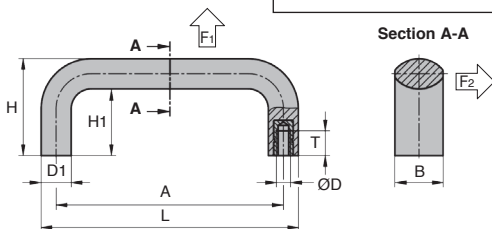


# Carrying handle

Thermoplastic

PGM

- Gripping handle for both pushing and pulling
- Rear mounting
- Material:  
Black glass-fibre reinforced thermoplastic,  
brass threaded insert

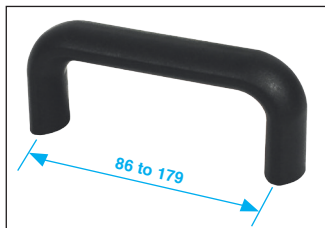

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-15%	On request	

Part number	A	B	ØD	D1	H	H1	L	T	F1 (N)	F2 (N)	Stock*	Price each 1 to 5
PGM86-M5	86	20	M5	12,5	40	28	98,5	10	4000	1500	✓	6,81 €
PGM86-M6	86	20	M6	12,5	40	28	98,5	9	4000	1500	✓	7,16 €
PGM94-M5	94	20	M5	12,5	40	28	106,5	10	3300	1600	✓	7,13 €
PGM94-M6	94	20	M6	12,5	40	28	106,5	9	3300	1600	✓	7,34 €
PGM117-M5	117	25	M5	16,0	50	34	134,0	10	4400	1800	✓	7,58 €
PGM117-M6	117	25	M6	16,0	50	34	134,0	9	4400	1800	-	8,02 €
PGM117-M8	117	25	M8	16,0	50	34	134,0	14	4400	1800	✓	8,24 €
PGM120-M5	120	25	M5	16,0	50	34	134,0	10	5200	2400	-	7,80 €
PGM120-M6	120	25	M6	16,0	50	34	134,0	9	5200	2400	✓	8,24 €
PGM120-M8	120	25	M8	16,0	50	34	134,0	14	5200	2400	-	8,47 €
PGM132-M5	132	25	M5	16,0	50	34	148,0	10	3700	2600	✓	8,02 €
PGM132-M6	132	25	M6	16,0	50	34	148,0	9	3700	2600	-	8,69 €
PGM132-M8	132	25	M8	16,0	50	34	148,0	14	3700	2600	-	8,92 €
PGM150-M6	150	29	M6	18,0	58	40	168,0	15	5900	1900	-	9,49 €
PGM150-M8	150	29	M8	18,0	58	40	168,0	14	5900	1900	-	9,59 €
PGM150-M10	150	29	M10	18,0	58	40	168,0	14	5900	1900	-	10,26 €
PGM179-M8	179	29	M8	18,0	58	40	197,0	14	3800	3200	✓	11,05 €
PGM179-M10	179	29	M10	18,0	58	40	197,0	14	3800	3200	-	11,37 €

Dimensions in mm

## Our other products



BPFHclip

Clip for ball transfer unit, Insert clip - Installing from above



BOXdhx

Boxed set of threaded dowel pins DIN7979D, Boxed set - extractable D...



BMM

Knurled knob - male, Knurled



PRF\_PF

Anchoring bracket for aluminium profile, Anchor



BPPEBLU

Ball transfer unit in blue certified plastic, for foodstuff sector



ADSR

Backlash free coupling Gerwah®, from 12.5 to 525Nm



GLB

Small 6 lobe threaded handle - female, Technopolymer - Stainless steel



PW\_PWG2

Worm - precision range, Steel




Q4

Double row radial contact ball bearing, Radial contact - Steel



DOMI120

 Accessories, Turntable



KB\_OP

Open precision linear bearing, Precision - steel



HLA24

Right angle spiro bevel gearbox, Up to 78Nm

## Complementary products



PGMSS

Stainless steel push/pull handle, Stainless steel



PO

Pull handle - Multi-sector, Smooth hole



PGMT

Pull handle, Stainless steel



PGM52-M4

Push/Pull handle, Aluminium