
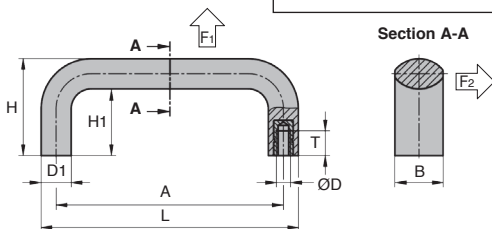


# Carrying handle

Thermoplastic

PGM

- Gripping handle for both pushing and pulling
- Rear mounting
- Material:  
Black glass-fibre reinforced thermoplastic,  
brass threaded insert

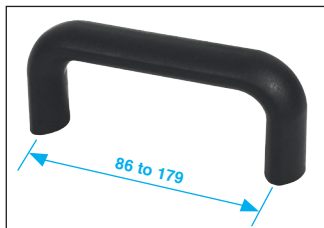

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-15%	On request	

Part number	A	B	ØD	D1	H	H1	L	T	F1 (N)	F2 (N)	Stock*	Price each 1 to 5
PGM86-M5	86	20	M5	12,5	40	28	98,5	10	4000	1500	✓	6,81 €
PGM86-M6	86	20	M6	12,5	40	28	98,5	9	4000	1500	✓	7,16 €
PGM94-M5	94	20	M5	12,5	40	28	106,5	10	3300	1600	✓	7,13 €
PGM94-M6	94	20	M6	12,5	40	28	106,5	9	3300	1600	✓	7,34 €
PGM117-M5	117	25	M5	16,0	50	34	134,0	10	4400	1800	✓	7,58 €
PGM117-M6	117	25	M6	16,0	50	34	134,0	9	4400	1800	-	8,02 €
PGM117-M8	117	25	M8	16,0	50	34	134,0	14	4400	1800	✓	8,24 €
PGM120-M5	120	25	M5	16,0	50	34	134,0	10	5200	2400	-	7,80 €
PGM120-M6	120	25	M6	16,0	50	34	134,0	9	5200	2400	✓	8,24 €
PGM120-M8	120	25	M8	16,0	50	34	134,0	14	5200	2400	-	8,47 €
PGM132-M5	132	25	M5	16,0	50	34	148,0	10	3700	2600	✓	8,02 €
PGM132-M6	132	25	M6	16,0	50	34	148,0	9	3700	2600	-	8,69 €
PGM132-M8	132	25	M8	16,0	50	34	148,0	14	3700	2600	-	8,92 €
PGM150-M6	150	29	M6	18,0	58	40	168,0	15	5900	1900	-	9,49 €
PGM150-M8	150	29	M8	18,0	58	40	168,0	14	5900	1900	-	9,59 €
PGM150-M10	150	29	M10	18,0	58	40	168,0	14	5900	1900	-	10,26 €
PGM179-M8	179	29	M8	18,0	58	40	197,0	14	3800	3200	✓	11,05 €
PGM179-M10	179	29	M10	18,0	58	40	197,0	14	3800	3200	-	11,37 €

Dimensions in mm

## Our other products



SSB  
Stainless steel bevel gear, 1:1



RJA10\_03  
Sealing strip, Clipping



PRF\_PA  
Angle plate for aluminium profile, Adjustable plate




SLB  
Indexing plunger, stainless steel



BEAB  
Knob star grip antibacterial, Star, anti-bacterial



 CHMR110  
Worm and wheel gear reducer, up to 980 Nm



PRES  
Manual workbench press accessory for PRES-3HR end PRES-4HR, Set of s...



PRFRTR  
Cross connector for aluminium profile, Cross connector



AT10courroie  
AT type timing belt, AT10 Steel cored polyurethane



BKGS  
Backlash free coupling Gerwah®, from 1.2 to 450Nm



BOX-TOR-A  
Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 28.17 x 3.53



BOX-TOR-H  
Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00

## Complementary products



PGMSS  
Stainless steel push/pull handle, Stainless steel



PO  
Pull handle - Multi-sector, Smooth hole



PGMT  
Pull handle, Stainless steel



PGM52-M4  
Push/Pull handle, Aluminium