
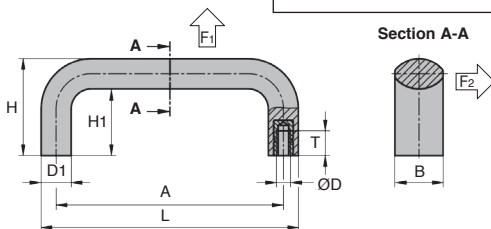


Carrying handle

Thermoplastic

PGM

- Gripping handle for both pushing and pulling
- Rear mounting
- Material:
Black glass-fibre reinforced thermoplastic,
brass threaded insert

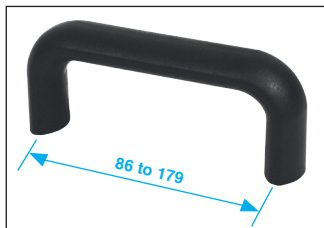

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	A	B	ØD	D1	H	H1	L	T	F1 (N)	F2 (N)	Stock*	Price each 1 to 5
PGM86-M5	86	20	M5	12,5	40	28	98,5	10	4000	1500	✓	6,81 €
PGM86-M6	86	20	M6	12,5	40	28	98,5	9	4000	1500	✓	7,16 €
PGM94-M5	94	20	M5	12,5	40	28	106,5	10	3300	1600	✓	7,13 €
PGM94-M6	94	20	M6	12,5	40	28	106,5	9	3300	1600	✓	7,34 €
PGM117-M5	117	25	M5	16,0	50	34	134,0	10	4400	1800	✓	7,58 €
PGM117-M6	117	25	M6	16,0	50	34	134,0	9	4400	1800	-	8,02 €
PGM117-M8	117	25	M8	16,0	50	34	134,0	14	4400	1800	✓	8,24 €
PGM120-M5	120	25	M5	16,0	50	34	134,0	10	5200	2400	-	7,80 €
PGM120-M6	120	25	M6	16,0	50	34	134,0	9	5200	2400	✓	8,24 €
PGM120-M8	120	25	M8	16,0	50	34	134,0	14	5200	2400	-	8,47 €
PGM132-M5	132	25	M5	16,0	50	34	148,0	10	3700	2600	✓	8,02 €
PGM132-M6	132	25	M6	16,0	50	34	148,0	9	3700	2600	-	8,69 €
PGM132-M8	132	25	M8	16,0	50	34	148,0	14	3700	2600	-	8,92 €
PGM150-M6	150	29	M6	18,0	58	40	168,0	15	5900	1900	-	9,49 €
PGM150-M8	150	29	M8	18,0	58	40	168,0	14	5900	1900	-	9,59 €
PGM150-M10	150	29	M10	18,0	58	40	168,0	14	5900	1900	-	10,26 €
PGM179-M8	179	29	M8	18,0	58	40	197,0	14	3800	3200	✓	11,05 €
PGM179-M10	179	29	M10	18,0	58	40	197,0	14	3800	3200	-	11,37 €

Dimensions in mm

Our other products



DCG

Suction cup, 2.5 bellows, natural rubber



SF_ZZ

Deep groove ball bearing, Stainless steel



M

Bellows cover, Accessory:



DER71

Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



VAP

Magnetic stud with central hole, With central hole



GCH

Linear ball slide - Stainless steel balls, Chariot - from 514 N to 1...



UCFL_SS

Stainless steel flanged bearing, Stainless steel



DOM180

Accessories, Fixing kit



TB8

Cylindrical roller thrust bearing, Steel




PM4

Worm and wheel set, Non hardened steel



BFDdII

 Locking pin for bushes, Nickel-plated steel



QN

Single row cylindrical roller bearing, Free outer ring

Complementary products



PGMSS

Stainless steel pull handle, Stainless steel



PO

Pull handle - Multi-sector, Smooth hole



PGMT

Pull handle, Stainless steel



PGM52-M4

Pull handle, Aluminium