
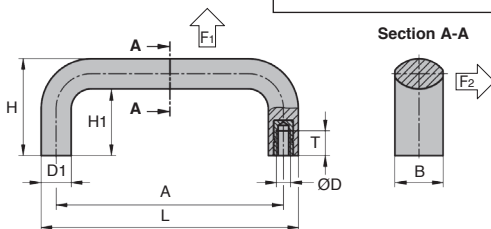


Carrying handle

Thermoplastic

PGM

- Gripping handle for both pushing and pulling
- Rear mounting
- Material:
Black glass-fibre reinforced thermoplastic,
brass threaded insert

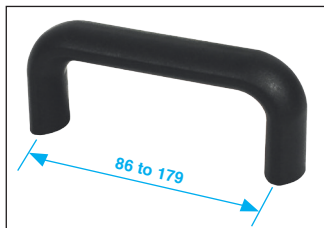

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-15%	On request	

Part number	A	B	ØD	D1	H	H1	L	T	F1 (N)	F2 (N)	Stock*	Price each 1 to 5
PGM86-M5	86	20	M5	12,5	40	28	98,5	10	4000	1500	✓	6,81 €
PGM86-M6	86	20	M6	12,5	40	28	98,5	9	4000	1500	✓	7,16 €
PGM94-M5	94	20	M5	12,5	40	28	106,5	10	3300	1600	✓	7,13 €
PGM94-M6	94	20	M6	12,5	40	28	106,5	9	3300	1600	✓	7,34 €
PGM117-M5	117	25	M5	16,0	50	34	134,0	10	4400	1800	✓	7,58 €
PGM117-M6	117	25	M6	16,0	50	34	134,0	9	4400	1800	-	8,02 €
PGM117-M8	117	25	M8	16,0	50	34	134,0	14	4400	1800	✓	8,24 €
PGM120-M5	120	25	M5	16,0	50	34	134,0	10	5200	2400	-	7,80 €
PGM120-M6	120	25	M6	16,0	50	34	134,0	9	5200	2400	✓	8,24 €
PGM120-M8	120	25	M8	16,0	50	34	134,0	14	5200	2400	-	8,47 €
PGM132-M5	132	25	M5	16,0	50	34	148,0	10	3700	2600	✓	8,02 €
PGM132-M6	132	25	M6	16,0	50	34	148,0	9	3700	2600	-	8,69 €
PGM132-M8	132	25	M8	16,0	50	34	148,0	14	3700	2600	-	8,92 €
PGM150-M6	150	29	M6	18,0	58	40	168,0	15	5900	1900	-	9,49 €
PGM150-M8	150	29	M8	18,0	58	40	168,0	14	5900	1900	-	9,59 €
PGM150-M10	150	29	M10	18,0	58	40	168,0	14	5900	1900	-	10,26 €
PGM179-M8	179	29	M8	18,0	58	40	197,0	14	3800	3200	✓	11,05 €
PGM179-M10	179	29	M10	18,0	58	40	197,0	14	3800	3200	-	11,37 €

Dimensions in mm

Our other products



RBNpl

Swivel castor with plate, Steel - rubber



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



BAGtr

Lead screw clamping collar, Aluminium



CHMR30

Worm and wheel gear reducer, up to 28 Nm



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide



PARF110

Pressed steel base rigid foot, Swivelling Ø110



 
HTD14M_55

HTD Heavy duty timing pulley, HTD14 Steel



DILC

Indexing plunger with cam, with cam



AC

Strike for toggle latch, 20mm



OPFL_OPPI

Numerical counter accessories, Locking



PW_PWG1

Worm - precision range, Steel



GE_ES_2RS

Spherical bushing, Steel / steel with seals

Complementary products



PGMSS

Stainless steel pull handle, Stainless steel



PO

Pull handle - Multi-sector, Smooth hole



PGMT

Pull handle, Stainless steel



PGM52-M4

Pull handle, Aluminium