

Front fixing handle



PGMT



Steel or stainless steel

- Push/pull handle
- Front fixing
- Materials:
 - Galvanised steel
 - Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanised

Economy range

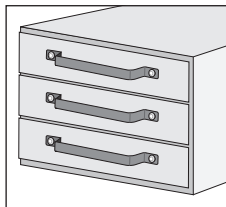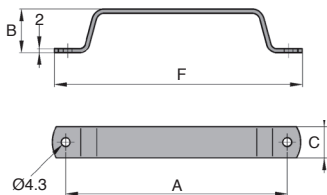

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



NKIA

Combined bearing with inner ring, Axial load in one direction



ZGO

Plastic spur gear, Machined plastic (delrin)



NSKB

Drylin® Rail end cap, Rail end cap



PRF JL5

Lip seal for panel, Door seal - Ø 5mm



SER69K

Quarter turn latch for the food industry, Stainless steel



BOXKK

Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



RDE-B

Sealing washer Hygienic Usit®, Stainless steel - Blue EPDM



PRF_PA

Angle plate for aluminium profile, Adjustable plate



F7-SF-SM

Multifunction display, Right angled



SLS

Bearing block for leadscrew, Floating



BDP2R

Adjustable support arm, Increased grip



GMK17_RG

Joint for guiding profile, Rounded

Complementary products



PGMT

Pull handle, Steel



PGM86-M5

Pull handle, Thermoplastic



PGM52-M4

Pull handle, Aluminium



PGM52-M4

Pull handle, Brass