

Front fixing handle





PGMT

Steel or stainless steel

- Push/pull handle
- Front fixing
- Materials:
 - Galvanised steel
 - Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanised

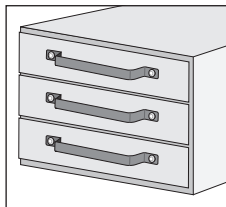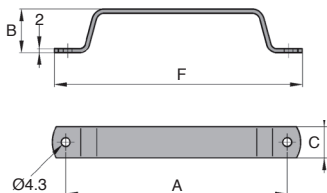

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



BOXKU

Boxed set of half round (Woodruff) keys NFE22179, Boxed set of half ...



AKD

Bellows coupling Gerwah®, from 22 to 600Nm



RFV63

Stainless steel worm and wheel gearbox, up to 152 Nm



STRIPF

Sealing brush strip, 1m length



RBntc

Swivel castor with central hole, Steel - rubber - with double brake



M

Bellows cover, Accessory:



VPRA_M

Handwheel with handle, Thermosetting plastic - galvanised steel hub



BPLE

Ball transfer unit push fit, Light



VBFP

Small 6 lobe threaded handle - female, Duroplast - Stainless



SHW

Plain washer, A2 Stainless steel



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120 with



CFF

Female rod ends DIN ISO12240-4, Steel / bronze

Complementary products



PGMT

Pull handle, Steel



PGM86-M5

Pull handle, Thermoplastic



PGM52-M4

Pull handle, Aluminium



PGM52-M4

Pull handle, Brass