

Front fixing handle



PGMT


 
Steel or stainless steel

- Push/pull handle
- Front fixing
- Materials:
 - Galvanised steel
 - Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanized

Economy range

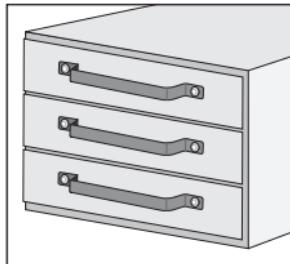

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3,68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6,43 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



ZG0
Plastic spur gear,
Machined plastic
(delrin)



RTK
BoWex® curved tooth
gear coupling, Nylon
and steel




ACM_AZ
Mounting bracket for
bonnet fastener, Hook



DCG
Suction cup, 2.5
bellows, silicon



STC
Shock Absorber - stop
collar, Universal
flange

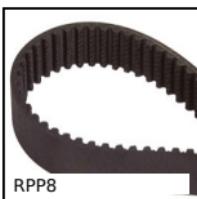

RPP8
RPP heavy duty
timing belt, RPP8



T10-BAR
T type tooth bar
stock, T10



KKP-AR
Linear bearing with
inclined ball tracks,
Heavy loads -20°
+20°



M1
Worm and wheel set,
Non hardened steel



CHMR90
Worm and wheel gear
reducer, up to 540
Nm



UGH50
H Type Guide units,
For Ø50 actuators



HFL
One way needle
bearing, Needle
bearing

Complementary products



PGMT
Pull handle, Steel



PGM86-M5
Push/Pull handle,
Thermoplastic



PGM52-M4
Push/Pull handle,
Aluminium



PGM52-M4
Push/Pull handle,
Brass