

Front fixing handle



PGMT



Steel or stainless steel

- Push/pull handle
- Front fixing
- Materials:
 - Galvanised steel
 - Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanised

Economy range

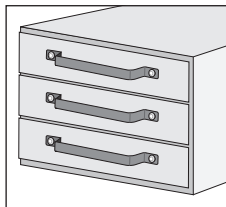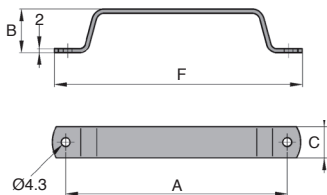

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

Our other products



 
ATZYSS
Stainless steel diablo shaped elasto mount,
Stainless steel



DIL
Lever operated locking bolt, lever clamp




PAMF100EB
Articulated foot with sheet metal base
Ø100, Articulated foot



LAT4
4A motorised linear actuator, 4 amperes



SBS_L
Chain link, Stainless steel

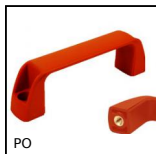

PO
Pull handle - Multi-sector, Tapped recessed insert




PITA
Locking bolt, with T handle



RAS
90°ball and socket joints DIN71802, Steel



 PM4
Worm and wheel set,
Hardened steel



PRF_JL4
Lip seal for panel,
Door seal - Ø 4mm



BPVMss
Stainless steel miniature ball transfer



PHTss
Pull handle, Up to 250 °C

Complementary products



PGMT
Pull handle, Steel