

# Front fixing handle



## PGMT



## Steel or stainless steel

**Economy range**

- Push/pull handle
- Front fixing
- Materials:  
Galvanised steel  
Stainless steel, 304

### Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanised

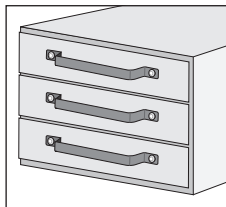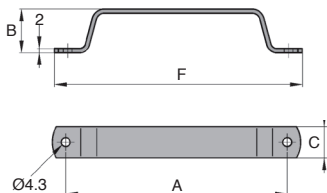

Typical application

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

**HPC**

WEB  
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

## Our other products



SCH

Horizontal hook toggle clamp,  
Horizontal Hook clamp - stainless steel



VLBG

Lifting ring, Rotating



ESSB

Bipod support base,  
Bipod support base



RBGtc

Swivel castor with  
central hole, Steel -  
grey rubber



UGH40

H Type Guide units,  
For Ø40 actuators



RTK

BoWex® curved tooth  
gear coupling, Nylon  
and steel



PRF\_BP

Doorstop for  
aluminium profile,  
Swing door stop



SUPCC

Self-centering  
clamping hub steel,  
With lock nut



UTKswc

Utilitrak® 3 wheels  
carriage, Series V  
precision steel wheel



AC156-157

Strike for toggle latch,  
25.5mm



PRF-CHAR-POU

Tool holder for  
aluminium profile,  
Moveable tool holder



CHT56

Asynchronous AC  
motor 0.09kW,  
0.09kW

## Complementary products



PGMT

Pull handle, Steel