

Front fixing handle



PGMT



Steel or stainless steel

- Push/pull handle
- Front fixing
- Materials:
 - Galvanised steel
 - Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanized

Economy range

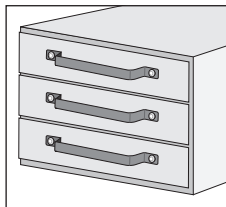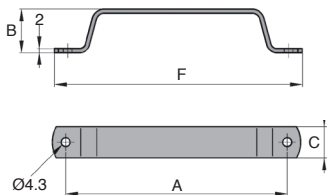

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



KITbuh

24V motorisation kit,
Planetary gears



CHAR7520

Spring hinges,
screwed



PRF4532

Standard aluminium
profile, 45 x 32 mm



CLSr-CLLr

Swivelling base clevis,
Steel long



MO

Worm, Machined
plastic (delrin)



712_015

Knob for clamping,
Knurled



HTD14M_55

HTD-type pulley for
RPP-type belt, HTD14
Cast



SLBE

Index bolt, Spacer for
SLB and SLBS index
bolts



 
BSCm

Knob for clamping,
Knurled threaded
torque



CHA_GC_14SS

Hinge (stainless
steel), To screw



M1

Wheel, Machined
plastic (delrin)



DOMI50

DOMILINE -
Accessories, Clamping
lever

Complementary products



PGMT

Carrying handle,
Stainless steel



PO

Housing handle - Multi-
sector, Smooth hole



PO

Housing handle - Multi-
sector, Tapped
recessed insert



PGM52-M4

Carrying handle,
Aluminium