

Front fixing handle





PGMT

Steel or stainless steel

- Push/pull handle
- Front fixing
- Materials:
 - Galvanised steel
 - Stainless steel, 304

Info.

- The handle is made from pre-galvanized steel.
- Cut edges and holes may therefore not be galvanised

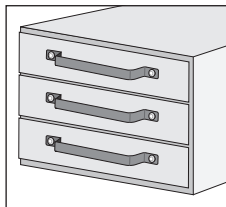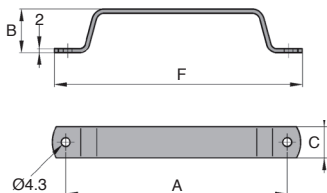

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-15%	On request

Part number	Material	Finish	A	B	C	F	Weight (g)	Stock*	Price each 1 to 5
PGMT107-4/AG	Galvanised steel	Natural	107	21	15	120	32	✓	3.68 €
PGMT107-4/SS	Stainless steel 304	Deburred	107	21	15	120	32	✓	6.43 €

Dimensions in mm

HPC

WEB
04/2019

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



PRF_ER
Joining bar for aluminium profile, joint bar



RCC_RCX
Spherical tilt washer - DIN6319, convex



PSG155
Spur gear - precision range, Stainless steel 316



AT5-10ECO
AT type timing pulley, Economy range - AT5 aluminium




WING
Manually tightened wing nut, Stainless steel DIN 314/315



AT5P_AT10P
Connecting plate for AT type timing belts, AT10



 CHASb89
Hinge without pin, Plastic hinge



EZYSS
Stainless steel cylindrical stop, stainless steel



PRF-SCREEN-4
Screen support, Support with 4 axes of rotation



HTD5M-BAR
HTD type tooth bar stock, HTD5



SSDB
Stainless steel bevel gear, 2:1



CFF
Female rod ends DIN ISO12240-4, Steel / bronze

Complementary products



PGMT
Pull handle, Steel



PGM86-M5
Pull handle, Thermoplastic



PGM52-M4
Pull handle, Aluminium



PGM52-M4
Pull handle, Brass