

Thermoplastic T handle



PGNT

Push-pull operation

- Handle with threaded insert or threaded spindle

- Material:

Black glass fibre reinforced thermoplastic


Threaded insert: brass

Threaded spindle: Chromed steel



Advantages

- Excellent grip


- Mechanical linkage applications

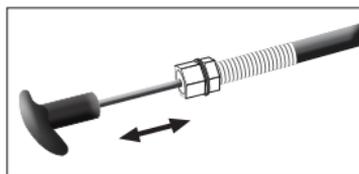

Typical application

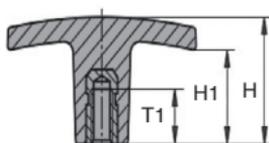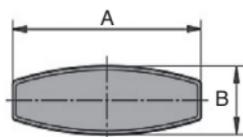

T handle with insert female

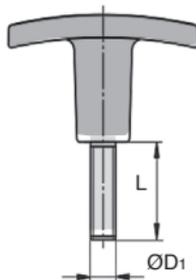

T handle with threaded spindle male

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	ØD1	ØD3	H	H1	T1	L	Weight (kg)	Price each
										Stock* 1 to 9
With threaded insert female										
PGNT40-M5	40	13	M5	13	30,5	20	10	-	0,011	✓ 2,86 €
PGNT50-M5	50	15	M5	14	24	16	10	-	0,013	✓ 2,96 €
PGNT60-M6	60	17	M6	16	31,5	23	12	-	0,017	✓ 3,96 €
PGNT71-M8	71	19,5	M8	20	36	19	20	-	0,028	✓ 6,16 €
PGNT71-M10	71	19,5	M10	20	36	19	20	-	0,030	- 6,77 €
PGNT80-M10	80	26	M10	26	39,5	26	25	-	0,048	✓ 7,91 €
PGNT80-M12	80	26	M12	26	39,5	26	25	-	0,056	- 9,22 €
With threaded spindle male										
PGNT40-M5-15	40	13	M5	13	30,5	20	-	15	-	✓ 1,53 €
PGNT50-M5-20	50	15	M5	14	24	16	-	20	-	✓ 2,70 €
PGNT50-M6-25	60	17	M6	16	31,5	23	-	25	-	✓ 3,05 €
PGNT71-M8-30	71	19,5	M8	20	36	19	-	30	-	✓ 4,56 €
PGNT71-M10-30	71	19,5	M10	20	36	19	-	30	-	✓ 5,22 €
PGNT80-M10-30	80	26	M10	26	39,5	26	-	30	-	✓ 6,03 €
PGNT80-M12-40	80	26	M12	26	39,5	26	-	40	-	- 7,16 €

*Depending on availability - Dimensions in mm