

Thermoplastic T handle

PGNT

Pull or push

- Handle with threaded insert or threaded stem

- Material:

Black glass fibre reinforced thermoplastic


Threaded insert: brass

Threaded stem: Chromed steel



Advantage

- Excellent grip


- Mechanical linkage applications

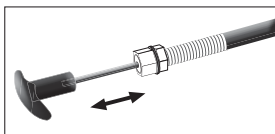

Typical application

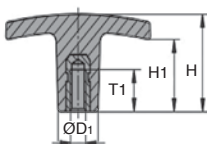 

T handle with insert

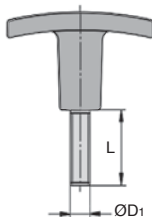

T handle with threaded stem

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	ØD1	ØD3	H	H1	T1	L	Weight (kg)	Price each 1 to 9
With threaded insert										
PGNT40-M5	40	13	M5	13	30,5	20	10	-	0,011	2,33 €
PGNT50-M5	50	15	M5	14	24	16	10	-	0,013	2,43 €
PGNT60-M6	60	17	M6	16	31,5	23	12	-	0,017	3,24 €
PGNT71-M8	71	19,5	M8	20	36	19	20	-	0,028	5,01 €
PGNT71-M10	71	19,5	M10	20	36	19	20	-	0,030	5,51 €
PGNT80-M10	80	26	M10	26	39,5	26	25	-	0,048	6,41 €
PGNT80-M12	80	26	M12	26	39,5	26	25	-	0,056	7,48 €
With threaded stem										
PGNT40-M5-15	40	13	M5	13	30,5	20	-	15	-	1,26 €
PGNT50-M5-20	50	15	M5	14	24	16	-	20	-	2,20 €
PGNT50-M6-25	60	17	M6	16	31,5	23	-	25	-	2,51 €
PGNT71-M8-30	71	19,5	M8	20	36	19	-	30	-	3,70 €
PGNT71-M10-30	71	19,5	M10	20	36	19	-	30	-	4,24 €
PGNT80-M10-30	80	26	M10	26	39,5	26	-	30	-	4,91 €
PGNT80-M12-40	80	26	M12	26	39,5	26	-	40	-	5,81 €

Dimensions in mm

Our other products



BAG-MISS
Split shaft collar with clamp lever, Stainless steel



CFF_SS
Female rod ends DIN ISO12240-4, Stainless steel / bronze - Economy r...



BSM_LOK
Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



DB
Steel bevel gear, 2:1



RFK28C
Hypoid gearbox - Stainless steel, up to 130 Nm



RCX-6
Spherical tilt washer - DIN6319, convex



CHA135
Screwed hinge, 135 degrees



PRF_PSA
Shaft support for aluminium profile, Linear guide shaft



TFR
Rigid manual tensioner, Fixed



V3RA_PTR
3-spoked handwheel with foldable handle, Polyamide



PP60
Worm and wheel gear reducer, from 17.80 to 34 Nm



NSO
Housing for open linear bearing, Opened - long

Complementary products



PGNT
Thermoplastic T handle, With threaded spindle



PCH
Knob for gripping, Mushroom