


Stock **Folding cylindrical revolving handle**

Technopolymer with steel
or **stainless steel** shaft

PGR

- **Folding cylindrical revolving handle with release mechanism**
- Operating element
- Material :
Body: Black glass fibre reinforced polyamide
Mechanism: Chromed steel or stainless steel

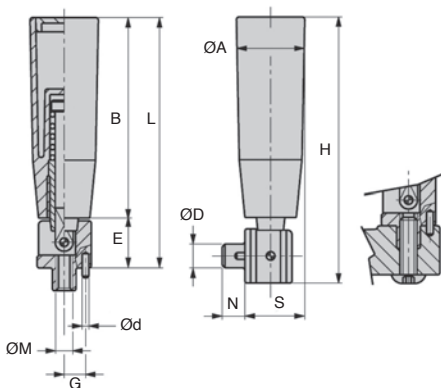

DISCOUNTS

Qty	1+	6+	10+	20+
Disc. List	-5%	-10%	On request	

Part number		ØA	H	S	ØD	N	ØM	Ød	G	F	E	B	L	Stock* Price each 1 to 5				
Steel	Stainless steel													Steel	Steel	Stainless steel		
PGR21-50	PGR21-50/SS	21	69	19	7	8	M5	2,5	6,3	4	16,5	50	66,5	✓	31,48	€	65,36	€
PGR23-70	PGR23-70/SS	23	92	21	8	8	M6	2,5	7,5	4	16,5	70	86,5	✓	34,29	€	70,94	€
PGR26-90	PGR26-90/SS	26	114	24	8	10	M6	2,5	7,5	4	20	90	110	✓	40,21	€	78,33	€

*Depending on availability - Dimensions in mm

Our other products



T39_T49

Extension spring in metre length steel, by the metre



PRF1945

Standard aluminium profile, 19 x 45 mm



PDM_PDV

Detectable plastic palm grip, blue thermoplastic



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm



MHWC

Double-disc flexible coupling, Double disk



MEP

Revolving handle for handwheel, Fixed



RDERSS

Stainless steel manual rigging screw, Stainless steel - manual



PTR

Idler chain sprocket, For standard applications



DBL880

Idler for slat top chain, Ranges 880 and 881




PSG35

Spur gear - precision range, Stainless steel 303



CHA60

 Rectangular hinge, drilled or countersunk, Rectangular, drilled or



SLVHlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot

Complementary products



PGR

Folding revolving handle for handwheel, Folding