


- For square tube \square 25 x 25
- Material: polyethylene
- Colour: black

Accessories


- Structural tube **TUBE**
- Support profiles **PSP**

Info.

- **PGT25-D** comprises 2 elements, top and bottom

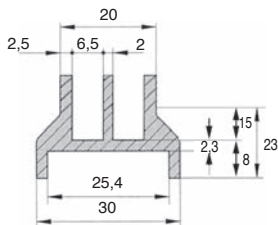


Top part

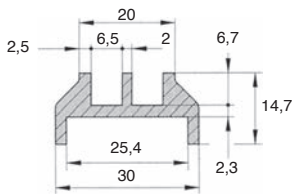

Profile type PGT-D

Bottom part

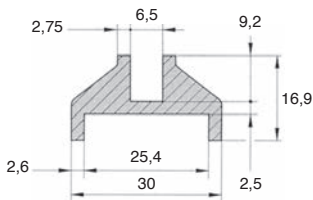

Profile type PGT-S



Typical application


DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Type	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 4
PGT25-S	Single	2000	0,53	✓	30,15 €
PGT25-D	Double	2000	0,85	-	104,15 €

*Depending on availability - Dimensions in mm

 Our other products



GLT3-76

Telescopic drawer,



SCH

Horizontal hook
toggle clamp,
Horizontal Hook
clamp - steel



OP7

Mechanical digital
position indicator, 5
numbers



GPBSS

Threaded spherical
knob, Stainless steel
304



TUBE25_25

Square Tube,
Aluminium or
Stainless steel



KITdog

24V DC motorisation
kit, Worm and wheel



P70

Worm and wheel gear
reducer, up to 164
Nm



HTD5M_15

HTD Heavy duty
timing pulley, HTD5
Steel



PSG055

Spur gear - precision
range, Stainless steel



RT70

Self-centering locking
Assembly,



INS100

Self tapping inserts-
coarse thread, Coarse



PR105

Articulated foot Ø103,
Ø 103

Complementary products



TUBE25_25

Square Tube,
Aluminium or
Stainless steel



NCT

Square tube
connector, Fixed
angle



NCT

Square tube
connector, Fixed
angle



NCT

Square tube
connector, Fixed
angle