

Handle



PHT For use in high temperatures up to 250°C

- Heavy-duty handle, resists high temperatures

- Working temperature:

Continuous operation: max + 150/160°C

Occasional use: + 250°C max

- Material:

Thermoplastic PPA, glass-fibre reinforced, black finish

Applications

- Ovens

- Machines generating heat

Mounting

- The mounting hole allows the handle to be secured with either a cylindrical or hexagonal headed screw.


- Front or rear mounting



150°C
Continuously



250°C
For short periods

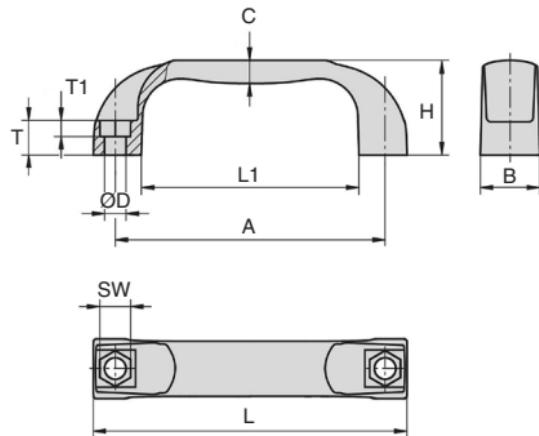

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Net	-5%	-15%	On request

Part N°	A	B	C	ØD	H	L	L1	SW	T	T1	Load (N)	Price each 1 to 5
PHT-117	117	26	10	9	41	136	94	13	15	8	1500	8,11 €
PHT-132	132	27	11	9	44	154	112	13	16	8	1500	12,87 €

All dimensions in mm



For use in high temperatures up to 250°C PHTss

- **Heavy-duty handle, resists high temperatures**

- **Working temperature:**

Continuous operation: max + 150/160°C

Occasional use: + 250°C max

- **Material:**

Thermoplastic PPA, glass-fibre reinforced,
black finish

Threaded insert: stainless steel



Applications

- This handle is larger than most and has an ergonomic design.
- Easy to clean thanks to a closed and smooth design.
- For use in the food or medical industries.



Mounting


- Rear mounting



**150°C
Continuously**



**250°C
For short periods**

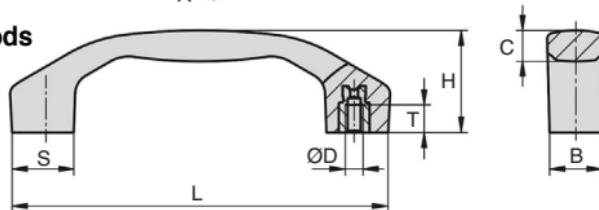

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Net	-5%	-15%	On request

Part N°	A	B	C	ØD	H	L	S	T	Charge (N)	Price each 1 to 5
PHT-100/SS	100	17	10,3	M5	34,0	122,5	20	9	1000	17,25 €
PHT-120/SS	120	21	12,4	M6	41,0	146,0	24	12	1000	20,68 €
PHT-140/SS	140	24	15,4	M8	46,5	170,0	28	12	1000	28,46 €

All dimensions in mm

Our other products



MFBC

Flexible Bellows coupling, Aluminium and Bronze - with clamping jaw



YG0

HEAVY DUTY spur gear, Steel 35NCD6



RIMtce

Locking castor, with central hole



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



PDM_PDV

Detectable plastic palm grip, by metal detectors



DCA

Suction cup, 1.5 bellows, natural rubber



S2B

Short linear bearing housing, Closed - Slim



GE1006

Elastic ringed latch, Hooks into a slot



CHTRB

Single and dual output gearboxes, Up to 53,1 Nm



PF20NM

Worm and wheel gear reducer, up to 5 Nm



VTA

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard

Complementary products



PO

Pull handle - Multi-sector, Tapped recessed insert



PGM52-M4

Push/Pull handle, Aluminium



PGMT

Pull handle, Steel



PGM52-M4

Push/Pull handle, Brass