

INDEX bolt with T handle



PITAss
PITBss

Stainless steel - thermoplastic

- **Indexing bolt with T-handle**
- The T-handle allows a good grip for easy clamping with low effort.
- **Materials:**

303 stainless steel

T-handle : thermoplastic dark grey RAL7021
or signal red RAL3020

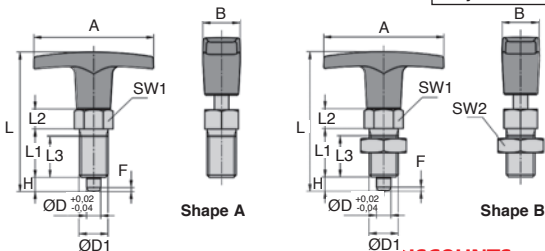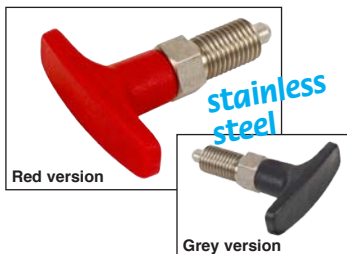

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	A	B	ØD	ØD1	L	L1	L2	L3	H	SW1	Spring force (N)		Price each 1 to 5
												Initial	Final	
Shape A - No nut														
PITA12-50/G/SS	Grey	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	15,99 €
PITA16-60/G/SS	Grey	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	21,21 €
PITA19-20/G/SS	Grey	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	36,27 €
PITA12-50/R/SS	Red	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	15,99 €
PITA16-60/R/SS	Red	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	21,21 €
PITA19-20/R/SS	Red	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	36,27 €
Shape B - With nut														
PITB12-50/G/SS	Grey	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	17,60 €
PITB16-60/G/SS	Grey	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	23,52 €
PITB19-20/G/SS	Grey	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	38,83 €
PITB12-50/R/SS	Red	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	17,60 €
PITB16-60/R/SS	Red	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	23,52 €
PITB19-20/R/SS	Red	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	38,83 €

All dimensions in mm

Our other products



PSG35
Spur gear - precision range, Stainless steel 303



NJM
Multiple junction clamp, Multiple



AT5P_AT10P
Connecting plate for AT type timing belts, AT5



 
PRF_JL6
Lip seal for panel, Door seal - Ø 6mm



MCLred
Reducing sleeve female/female, Cylindrical - stainless steel



BPHF
Ball transfer unit push fit, Heavy



MBronde
Stop washer, Stop washer MB



MBF
Threaded blocking clamp, Threaded locking clamp



PX_PO
Carrying handle, standard



BPTR_M
End cap with threaded insert for round tube, With threaded insert



PSG125S
Spur gear - precision range, Stainless steel 316



PSG125HC
Skive hobbed spur gears - precision range, Case hardened steel 20NCD2

Complementary products



SLBS
Stainless steel indexing plunger, Stainless steel



SLBE
Indexing plunger - Spacer, Spacer for SLB and SLBS index bolts



DIL
Lever operated locking bolt, lever clamp



DIA
Ring operated locking bolt, with ring