

Index bolt with T handle

PITA
PITB

Steel - thermoplastic

- Indexing bolt with T-handle

- The T-handle allows a good grip for easy clamping with low effort

- Materials:

Burnished steel, class 5.8

T-handle : thermoplastic dark grey
RAL7021 or signal red RAL3020

 

NEW!





Grey version



Red version

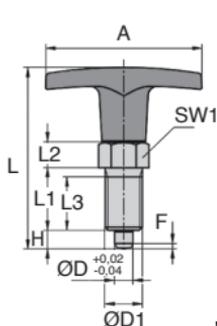

Shape A

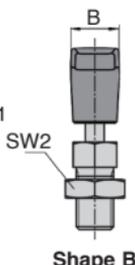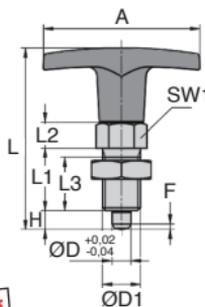

Shape B

✓ IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	A	B	ØD	ØD1	L	L1	L2	L3	H	SW1	Spring force (N)		Price each 1 to 5
												F1	F2	
Shape A - No nut														
PITA12-50/G	Grey	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	10,39 €
PITA16-60/G	Grey	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	13,40 €
PITA19-20/G	Grey	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	15,56 €
PITA12-50/R	Red	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	10,39 €
PITA16-60/R	Red	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	13,40 €
PITA19-20/R	Red	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	15,56 €
Shape B - With nut														
PITB12-50/G	Grey	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	10,75 €
PITB16-60/G	Grey	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	14,30 €
PITB19-20/G	Grey	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	16,33 €
PITB12-50/R	Red	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	10,75 €
PITB16-60/R	Red	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	14,30 €
PITB19-20/R	Red	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	16,33 €


*Depending on availability - Dimensions in mm

Index bolt with T handle

Stainless steel - thermoplastic

PITAss
PITBss

- Indexing bolt with T-handle
- The T-handle allows a good grip for easy clamping with low effort
- Materials:
303 stainless steel
T-handle : thermoplastic dark grey RAL7021
or signal red RAL3020

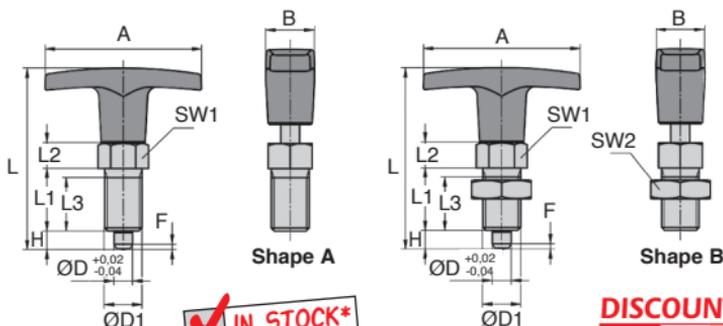

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Colour	A	B	ØD	ØD1	L	L1	L2	L3	H	SW1	Spring force (N)		Price each 1 to 5
												F1	F2	
Shape A - No nut														
PITA12-50/G/SS	Grey	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	18,04 €
PITA16-60/G/SS	Grey	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	23,92 €
PITA19-20/G/SS	Grey	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	32,72 €
PITA12-50/R/SS	Red	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	18,04 €
PITA16-60/R/SS	Red	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	23,92 €
PITA19-20/R/SS	Red	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	32,72 €
Shape B - With nut														
PITB12-50/G/SS	Grey	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	19,88 €
PITB16-60/G/SS	Grey	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	26,53 €
PITB19-20/G/SS	Grey	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	35,06 €
PITB12-50/R/SS	Red	50	15,5	6	M12x1,5	58	20	8	17	6	14	6	14	19,88 €
PITB16-60/R/SS	Red	60	18,0	8	M16x1,5	77	26	10	23	8	19	15	35	26,53 €
PITB19-20/R/SS	Red	72	19,0	10	M20x1,5	84	28	12	25	10	22	15	34	35,06 €

*Depending on availability - Dimensions in mm