


Flat magnet




PLA

NdFeB


- **Shielded system**
- NdFeB magnets offer 10-20% more attraction force than SmCo magnets
- Max working temp : +80°C
- **Material, finish**
Galvanised steel body,
Magnetic core NeFeB

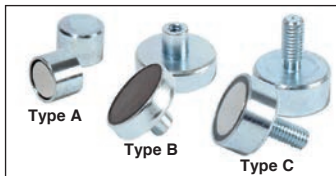


INCREASED STOCK

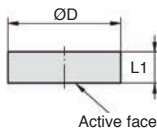

Type A

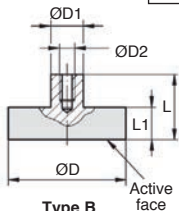

Type B

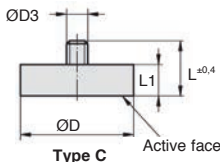

Type C

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	Forme	ØD	ØD1	ØD2	ØD3	L	L1	Attraction force		Price each
								(N)	(g)	
PLA6-4/A	A	6 ^{+0,15}	-	-	-	-	4,5	5	1,0	✓ 3,24 €
PLA8-4/A	A	8 ^{+0,15}	-	-	-	-	4,5	13	1,5	✓ 3,36 €
PLA10-4/A	A	10 ^{+0,15}	-	-	-	-	4,5	25	2,5	✓ 3,92 €
PLA13-4/A	A	13 ^{+0,15}	-	-	-	-	4,5	60	4,5	✓ 4,05 €
PLA16-4/A	A	16 ^{+0,15}	-	-	-	-	4,5	95	6,5	✓ 4,85 €
PLA20-6/A	A	20 ^{+0,15}	-	-	-	-	6,0	140	15,0	✓ 7,30 €
PLA25-7/A	A	25 ^{+0,15}	-	-	-	-	7,0	200	22,0	✓ 10,95 €
PLA32-7/A	A	32 ^{+0,20}	-	-	-	-	7,0	350	40,0	✓ 17,17 €
PLA6-4/B	B	6 ^{+0,15}	6	M3	-	11,5	4,5	5	1,5	- 4,05 €
PLA8-4/B	B	8 ^{+0,15}	6	M3	-	11,5	4,5	13	2,0	- 4,20 €
PLA10-4/B	B	10 ^{+0,15}	6	M3	-	11,5	4,5	25	3,0	✓ 4,81 €
PLA13-4/B	B	13 ^{+0,15}	6	M3	-	11,5	4,5	60	5,0	✓ 5,02 €
PLA16-4/B	B	16 ^{+0,15}	6	M4	-	11,5	4,5	95	7,5	✓ 5,87 €
PLA20-6/B	B	20 ^{+0,15}	8	M4	-	13,0	6,0	140	16,0	- 9,98 €
PLA25-7/B	B	25 ^{+0,15}	8	M4	-	14,0	7,0	200	25,0	- 14,82 €
PLA32-7/B	B	32 ^{+0,20}	10	M5	-	15,5	7,0	350	48,0	✓ 20,02 €
PLA10-4/C	C	10 ^{+0,15}	-	-	M3	11,5	4,5	25	3,0	✓ 4,58 €
PLA13-4/C	C	13 ^{+0,15}	-	-	M5	12,5	4,5	60	5,0	✓ 5,02 €
PLA16-4/C	C	16 ^{+0,15}	-	-	M6	12,5	4,5	95	8,0	✓ 5,91 €
PLA20-6/C	C	20 ^{+0,15}	-	-	M6	16,0	6,0	140	16,0	✓ 10,01 €
PLA25-7/C	C	25 ^{+0,15}	-	-	M6	17,0	7,0	200	25,0	✓ 14,82 €
PLA32-7/C	C	32 ^{+0,20}	-	-	M6	17,0	7,0	350	48,0	✓ 20,38 €

Dimensions in mm

Our other products



RCC_RCX

Spherical tilt washer -
DIN6319, concave



DOMI120

Accessories, Plate



MDB_MTB

Moulded plastic bevel
gear (nylon), 3:1



ADL_M

Male eye bolt
conforms to DIN580,
Steel



BLHB30

Right angled gearbox,
bored shafts, up to
4.47 Nm



FDS

Flexible drive shaft,
Masterflex® Steel,
with PVC casing



SLB

Indexing plunger,
steel class 5.8



 
PRF_FIX_UNI

Universal fastener for
aluminium profile,
Universal




PTGT

Tensioner pulley, For
V belts



VKM

 Square steel nut,
Steel - 1 thread



SLS

Bearing block for
leadscrew, Fixed



PGT

Sliding profile, Sliding
panel support

Complementary products



PLA

Flat magnet, Flat
magnet



PLA

Flat magnet, Flat
magnet with threaded
hole