


Flat magnet




PLA

NdFeB


- **Shielded system**
- NdFeB magnets offer 10-20% more attraction force than SmCo magnets
- Max working temp : +80°C
- **Material, finish**
Galvanised steel body,
Magnetic core NeFeB

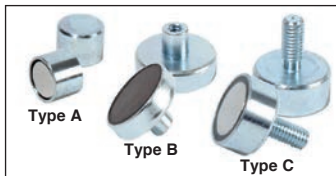


INCREASED STOCK

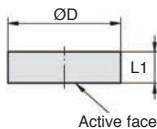

Type A

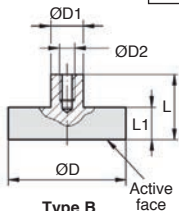

Type B

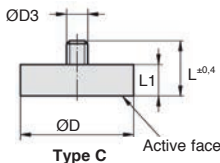

Type C

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	Forme	ØD	ØD1	ØD2	ØD3	L	L1	Attraction force		Price each
								(N)	(g)	
PLA6-4/A	A	6 ^{+0,15}	-	-	-	-	4,5	5	1,0	3,24 €
PLA8-4/A	A	8 ^{+0,15}	-	-	-	-	4,5	13	1,5	3,36 €
PLA10-4/A	A	10 ^{+0,15}	-	-	-	-	4,5	25	2,5	3,92 €
PLA13-4/A	A	13 ^{+0,15}	-	-	-	-	4,5	60	4,5	4,05 €
PLA16-4/A	A	16 ^{+0,15}	-	-	-	-	4,5	95	6,5	4,85 €
PLA20-6/A	A	20 ^{+0,15}	-	-	-	-	6,0	140	15,0	7,30 €
PLA25-7/A	A	25 ^{+0,15}	-	-	-	-	7,0	200	22,0	10,95 €
PLA32-7/A	A	32 ^{+0,20}	-	-	-	-	7,0	350	40,0	17,17 €
PLA6-4/B	B	6 ^{+0,15}	6	M3	-	11,5	4,5	5	1,5	4,05 €
PLA8-4/B	B	8 ^{+0,15}	6	M3	-	11,5	4,5	13	2,0	4,20 €
PLA10-4/B	B	10 ^{+0,15}	6	M3	-	11,5	4,5	25	3,0	4,81 €
PLA13-4/B	B	13 ^{+0,15}	6	M3	-	11,5	4,5	60	5,0	5,02 €
PLA16-4/B	B	16 ^{+0,15}	6	M4	-	11,5	4,5	95	7,5	5,87 €
PLA20-6/B	B	20 ^{+0,15}	8	M4	-	13,0	6,0	140	16,0	9,98 €
PLA25-7/B	B	25 ^{+0,15}	8	M4	-	14,0	7,0	200	25,0	14,82 €
PLA32-7/B	B	32 ^{+0,20}	10	M5	-	15,5	7,0	350	48,0	20,02 €
PLA10-4/C	C	10 ^{+0,15}	-	-	M3	11,5	4,5	25	3,0	4,58 €
PLA13-4/C	C	13 ^{+0,15}	-	-	M5	12,5	4,5	60	5,0	5,02 €
PLA16-4/C	C	16 ^{+0,15}	-	-	M6	12,5	4,5	95	8,0	5,91 €
PLA20-6/C	C	20 ^{+0,15}	-	-	M6	16,0	6,0	140	16,0	10,01 €
PLA25-7/C	C	25 ^{+0,15}	-	-	M6	17,0	7,0	200	25,0	14,82 €
PLA32-7/C	C	32 ^{+0,20}	-	-	M6	17,0	7,0	350	48,0	20,38 €

Dimensions in mm

Our other products



PSG15

Spur gear - precision range, Stainless steel 303



BOXdhx

Boxed set of threaded dowel pins DIN7979D, Boxed set - extractable D...



ERC

Quick fitting cable terminal, Eye version



M1

Worm and wheel set, Hardened steel



T10courroie

T type timing belt, T10 Steel cored polyurethane



PM2

Worm and wheel set, Bronze



AC156-157

Strike for toggle latch, 25.5mm



RPP

Connecting plate for RPP type timing belts, RPP8



CHAPAMss

Weld-on hinge with flat end, Stainless



ADL_F

Female eye bolt conforms to DIN582,



CABPVC

PVC covered galvanised steel



R204

Die spring ISO10243, Average

Complementary products

transparen...



PLA

Flat magnet, Flat magnet



PLA

Flat magnet, Flat magnet with threaded hole



PLMcr

Magnetic stud with hook, With hook